

Steel spur gear



Module 3,0

C45 steel

- Economy range of gears

- Pressure angle 20°


- Material:

C45 steel UNI7845

Info


- Pilot bore information is given as a guide only and may vary between batches

- Gear should be finished to suit the application, **we are unable to offer this service**

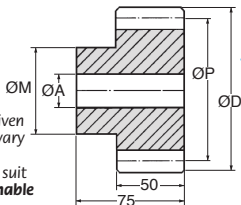

Economy range

Supplied pre-bored

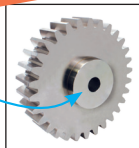

DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-5%	On request

Part number	Z Teeth	ØP PCD	ØD External	ØM Boss	ØA Pilot bore		Price each 1 to 3
G3-12/ECO	12	36	42	25	12	✓	6,52 €
G3-13/ECO	13	39	45	25	12	-	7,79 €
G3-14/ECO	14	42	48	30	12	✓	8,07 €
G3-15/ECO	15	45	51	35	12	✓	9,09 €
G3-16/ECO	16	48	54	38	15	✓	10,56 €
G3-17/ECO	17	51	57	42	15	✓	11,24 €
G3-18/ECO	18	54	60	45	15	✓	12,02 €
G3-19/ECO	19	57	63	45	15	-	12,38 €
G3-20/ECO	20	60	66	45	15	✓	13,84 €
G3-21/ECO	21	63	69	45	15	✓	16,15 €
G3-22/ECO	22	66	72	50	15	✓	16,65 €
G3-23/ECO	23	69	75	50	15	✓	18,27 €
G3-24/ECO	24	72	78	50	16	✓	18,65 €
G3-25/ECO	25	75	81	60	16	✓	20,76 €
G3-26/ECO	26	78	84	60	16	✓	22,21 €
G3-27/ECO	27	81	87	60	16	✓	23,76 €
G3-28/ECO	28	84	90	60	16	✓	26,40 €
G3-29/ECO	29	87	93	60	16	✓	27,31 €
G3-30/ECO	30	90	96	60	16	✓	28,36 €
G3-31/ECO	31	93	99	70	20	✓	29,39 €
G3-32/ECO	32	96	102	70	20	✓	30,92 €
G3-33/ECO	33	99	105	70	20	✓	31,04 €
G3-34/ECO	34	102	108	70	20	✓	32,27 €
G3-35/ECO	35	105	111	70	20	✓	34,18 €
G3-36/ECO	36	108	114	70	20	✓	36,74 €
G3-37/ECO	37	111	117	80	20	✓	38,16 €
G3-38/ECO	38	114	120	80	20	✓	38,77 €
G3-39/ECO	39	117	123	80	20	✓	39,87 €
G3-40/ECO	40	120	126	80	20	✓	40,08 €
G3-41/ECO	41	123	129	90	20	✓	46,78 €
G3-42/ECO	42	126	132	90	20	✓	52,51 €
G3-43/ECO	43	129	135	90	20	✓	55,62 €
G3-44/ECO	44	132	138	90	20	✓	57,10 €
G3-45/ECO	45	135	141	90	20	✓	60,33 €
G3-46/ECO	46	138	144	90	20	✓	64,19 €
G3-47/ECO	47	141	147	90	20	✓	67,07 €
G3-48/ECO	48	144	150	100	20	✓	68,39 €

Dimensions in mm

Our other products



MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



ACLBDB

Closing mechanism for aluminium profile, Dual ball catch



D-PAR_SS

Stainless steel elastomeric mount, stainless steel



TOL

Swivel head, Long



DOMI80

Domino 80 adjustable slide, Slide DOMILINE 80



PRF_CLIP_22

Cable clip for aluminium profile, For electric and pneumatic cables



EAR

Bearing locknut, Self locking locknut - nylon lock washer



ACLRP

Wheel for aluminium profile, Integrated bearing



PAT123

Pressed stainless steel articulating foot Ø123, Ø 123



AKN

Bellows coupling Gerwah®, from 22 to 180Nm



PRF-CHAR-POU

Tool holder for aluminium profile, Moveable tool holder



HDSS

Needle roller double universal joint - Stainless steel, Heavy duty

Complementary products



G3

Steel spur gear, Steel 20NCD2



CLG3

Moulded plastic spur gear, Moulded plastic (nylon)



ZG3

Plastic spur gear, Machined plastic (delrin)



YG3

HEAVY DUTY spur gear, Steel 35NCD6