

Steel spur gear



Module 3,0

C45 steel

- Economy range of gears

- Pressure angle 20°


- Material:

C45 steel UNI7845

Info


- Pilot bore information is given as a guide only and may vary between batches

- Gear should be finished to suit the application, **we are unable to offer this service**

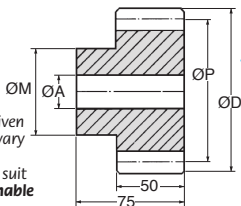

Economy range

Supplied pre-bored

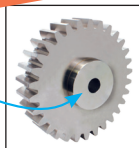

DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-5%	On request

Part number	Z Teeth	ØP PCD	ØD External	ØM Boss	ØA Pilot bore		Price each 1 to 3
G3-12/ECO	12	36	42	25	12	✓	6,52 €
G3-13/ECO	13	39	45	25	12	-	7,79 €
G3-14/ECO	14	42	48	30	12	✓	8,07 €
G3-15/ECO	15	45	51	35	12	✓	9,09 €
G3-16/ECO	16	48	54	38	15	✓	10,56 €
G3-17/ECO	17	51	57	42	15	✓	11,24 €
G3-18/ECO	18	54	60	45	15	✓	12,02 €
G3-19/ECO	19	57	63	45	15	-	12,38 €
G3-20/ECO	20	60	66	45	15	✓	13,84 €
G3-21/ECO	21	63	69	45	15	✓	16,15 €
G3-22/ECO	22	66	72	50	15	✓	16,65 €
G3-23/ECO	23	69	75	50	15	✓	18,27 €
G3-24/ECO	24	72	78	50	16	✓	18,65 €
G3-25/ECO	25	75	81	60	16	✓	20,76 €
G3-26/ECO	26	78	84	60	16	✓	22,21 €
G3-27/ECO	27	81	87	60	16	✓	23,76 €
G3-28/ECO	28	84	90	60	16	✓	26,40 €
G3-29/ECO	29	87	93	60	16	✓	27,31 €
G3-30/ECO	30	90	96	60	16	✓	28,36 €
G3-31/ECO	31	93	99	70	20	✓	29,39 €
G3-32/ECO	32	96	102	70	20	✓	30,92 €
G3-33/ECO	33	99	105	70	20	✓	31,04 €
G3-34/ECO	34	102	108	70	20	✓	32,27 €
G3-35/ECO	35	105	111	70	20	✓	34,18 €
G3-36/ECO	36	108	114	70	20	✓	36,74 €
G3-37/ECO	37	111	117	80	20	✓	38,16 €
G3-38/ECO	38	114	120	80	20	✓	38,77 €
G3-39/ECO	39	117	123	80	20	✓	39,87 €
G3-40/ECO	40	120	126	80	20	✓	40,08 €
G3-41/ECO	41	123	129	90	20	✓	46,78 €
G3-42/ECO	42	126	132	90	20	✓	52,51 €
G3-43/ECO	43	129	135	90	20	✓	55,62 €
G3-44/ECO	44	132	138	90	20	✓	57,10 €
G3-45/ECO	45	135	141	90	20	✓	60,33 €
G3-46/ECO	46	138	144	90	20	✓	64,19 €
G3-47/ECO	47	141	147	90	20	✓	67,07 €
G3-48/ECO	48	144	150	100	20	✓	68,39 €

Dimensions in mm

Our other products



CABtool
Fitting cable tools,
Cutting tools




MSP38
Masterplate®
glueable insert Ø38,
Cylindrical Ø38 with
tapped ins...



TBD
Manual leadscrew
table with opposing
threads, 20kg



CHB
Reaction arm, CHB
gear reducers
reaction arm

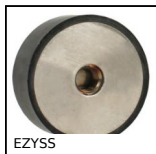

EZYSS
Stainless steel
cylindrical stop,
stainless steel



BSCf
Knurled torque knobs
- female, Knurled
threaded torque



SBF
Sealed flange bearing
unit for Food Industry,
cover



 
PVL
Small lobed handle,
Polyamide



ACLBMC
Detector support for
aluminium profile,
Sensor holder



KB_WW
Closed linear
precision bearing,
Economy range



AC
Strike for toggle latch,
15mm



TBD
Manual leadscrew
table with opposing
threads, 40kg

Complementary products



G3
Steel spur gear, Steel
20NCD2



CLG3
Moulded plastic spur
gear, Moulded plastic
(nylon)



ZG3
Plastic spur gear,
Machined plastic
(delrin)



YG3
HEAVY DUTY spur
gear, Steel 35NCD2