

### - Economy range of gears

- Pressure angle 20°


- Material:

C45 steel UNI7845

### Info

- Pilot bore information is given as a guide only and may vary between batches

- Gear should be finished to suit the application, **we are unable to offer this service**

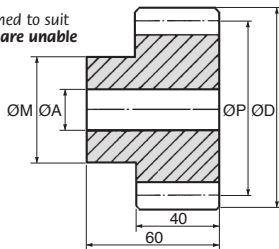

Supplied pre-bored



Economy range


### DISCOUNTS

 Qty	1+	4+	10+
Disc.	List	-5%	On request

Part number	Z Teeth	ØP PCD	ØD External	ØM Boss	ØA Pilot bore	Stock*	Price each 1 to 3
G4-12/ECO	12	48	56	35	14	✓	11,76 €
G4-13/ECO	13	52	60	40	14	✓	13,71 €
G4-14/ECO	14	56	64	45	14	✓	15,59 €
G4-15/ECO	15	60	68	45	14	✓	17,67 €
G4-16/ECO	16	64	72	50	15	✓	20,33 €
G4-17/ECO	17	68	76	50	15	✓	22,76 €
G4-18/ECO	18	72	80	50	15	✓	24,22 €
G4-19/ECO	19	76	84	60	15	✓	24,86 €
G4-20/ECO	20	80	88	60	15	✓	26,69 €
G4-21/ECO	21	84	92	70	20	✓	27,86 €
G4-22/ECO	22	88	96	70	20	✓	30,44 €
G4-23/ECO	23	92	100	75	20	✓	33,89 €
G4-24/ECO	24	96	104	75	20	✓	35,96 €
G4-25/ECO	25	100	108	75	20	✓	37,97 €
G4-26/ECO	26	104	112	75	20	✓	40,40 €
G4-27/ECO	27	108	116	75	20	✓	44,59 €
G4-28/ECO	28	112	120	75	20	✓	47,21 €
G4-29/ECO	29	116	124	75	20	✓	48,78 €
G4-30/ECO	30	120	128	75	20	✓	51,82 €
G4-31/ECO	31	124	132	80	20	✓	52,91 €
G4-32/ECO	32	128	136	80	20	✓	54,76 €
G4-33/ECO	33	132	140	80	20	✓	57,43 €
G4-34/ECO	34	136	144	80	20	✓	60,03 €
G4-35/ECO	35	140	148	80	20	✓	62,60 €
G4-36/ECO	36	144	152	80	20	✓	70,74 €

Dimensions in mm

## Our other products



PM3

Worm and wheel set,  
Machined plastic  
(delrin)




PT820

Drive sprocket for slat  
top chain, Ranges 820  
and 815



SER

 Magnetic doorstop for  
aluminium profile,  
Magnetic doorstop



SLHHlok

Horizontal toggle  
clamp, Horizontal  
toggle clamp /  
horizontal foot



AT5M AT10M

AT type timing belt  
per metre, AT10 Steel  
cored polyurethane



ESCON

Speed controller 5A  
accessories, Kit of 4  
cables for DC motor



UFX

Uneflex® elastic  
coupling, range



SHSS

Shoulder screw  
stainless steel 416,  
Pre-treated 416  
stainless steel



CHMR30

Worm and wheel gear  
reducer, up to 28 Nm



HLC19

Right angle spiro  
bevel gearbox, Up to  
43Nm



AWMP


Aluminium shaft for  
linear guide,  
Aluminium



SH1

Parallel axis helical  
gear, Machined plastic  
(delrin)

## Complementary products

 

MR\_MMR

Metric section rack,  
Steel



G4

Steel spur gear, Steel  
20NCD2



ZG4

Plastic spur gear,  
Machined plastic  
(delrin)



YG4

HEAVY DUTY spur  
gear, Steel 35NCD6