


- **Economy range of gears**
- Pressure angle 20°
- Material:
C45 steel UNI7845

Info

- Pilot bore information is given as a guide only and may vary between batches
- Gear should be finished to suit the application, **we are unable to offer this service**

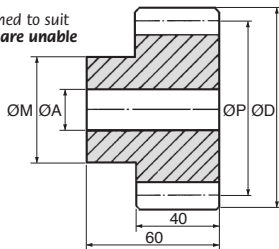

Supplied pre-bored



Economy range

DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-5%	On request

Part number	Z Teeth	ØP PCD	ØD External	ØM Boss	ØA Pilot bore	Stock*	Price each 1 to 3
G4-12/ECO	12	48	56	35	14	✓	11,76 €
G4-13/ECO	13	52	60	40	14	✓	13,71 €
G4-14/ECO	14	56	64	45	14	✓	15,59 €
G4-15/ECO	15	60	68	45	14	✓	17,67 €
G4-16/ECO	16	64	72	50	15	✓	20,33 €
G4-17/ECO	17	68	76	50	15	✓	22,76 €
G4-18/ECO	18	72	80	50	15	✓	24,22 €
G4-19/ECO	19	76	84	60	15	✓	24,86 €
G4-20/ECO	20	80	88	60	15	✓	26,69 €
G4-21/ECO	21	84	92	70	20	✓	27,86 €
G4-22/ECO	22	88	96	70	20	✓	30,44 €
G4-23/ECO	23	92	100	75	20	✓	33,89 €
G4-24/ECO	24	96	104	75	20	✓	35,96 €
G4-25/ECO	25	100	108	75	20	✓	37,97 €
G4-26/ECO	26	104	112	75	20	✓	40,40 €
G4-27/ECO	27	108	116	75	20	✓	44,59 €
G4-28/ECO	28	112	120	75	20	✓	47,21 €
G4-29/ECO	29	116	124	75	20	✓	48,78 €
G4-30/ECO	30	120	128	75	20	✓	51,82 €
G4-31/ECO	31	124	132	80	20	✓	52,91 €
G4-32/ECO	32	128	136	80	20	✓	54,76 €
G4-33/ECO	33	132	140	80	20	✓	57,43 €
G4-34/ECO	34	136	144	80	20	✓	60,03 €
G4-35/ECO	35	140	148	80	20	✓	62,60 €
G4-36/ECO	36	144	152	80	20	✓	70,74 €

Dimensions in mm

Our other products



RURp
Swivel castor with double brake, Polyurethane - Aluminium rim (Free)



P45
Worm and wheel gear reducer, up to 40 Nm



PRF_PL_9090
Joining plate for aluminium profile, Joint plate - 90x90 mm



CLASS
Stainless steel indexing handle - female, Stainless steel



PRF_PSP_PR
Dual purpose strip and cover for aluminium profile, Inserts into slot



PCS_PA6
Plastic sprocket, 9.525mm (DIN 06B-1)



RBGpl
Swivel castor with double brake, Steel - grey rubber



LVT
Miniature motorised actuator 1A, 1 amper



STRIP
Sealing brush strip, 3m length



PTA80ssEB
Articulated foot with sheet metal base

 


SSDB
Stainless steel bevel gear, 2:1



ZBconique
Machined plastic bevel gear, 1:1

Complementary products



MR_MMR
Metric section rack, Steel



G4
Steel spur gear, Steel 20NCD2



ZG4
Plastic spur gear, Machined plastic (delrin)



YG4
HEAVY DUTY spur gear, Steel 35NCD6