


- **Economy range of gears**
- Pressure angle 20°
- Material:
C45 steel UNI7845

Info

- Pilot bore information is given as a guide only and may vary between batches
- Gear should be finished to suit the application, **we are unable to offer this service**

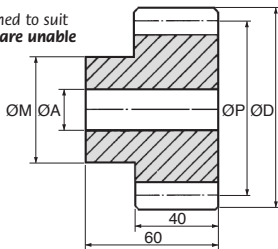

Supplied pre-bored



Economy range


DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-5%	On request

Part number	Z Teeth	ØP PCD	ØD External	ØM Boss	ØA Pilot bore	Stock*	Price each 1 to 3
G4-12/ECO	12	48	56	35	14	✓	11,76 €
G4-13/ECO	13	52	60	40	14	✓	13,71 €
G4-14/ECO	14	56	64	45	14	✓	15,59 €
G4-15/ECO	15	60	68	45	14	✓	17,67 €
G4-16/ECO	16	64	72	50	15	✓	20,33 €
G4-17/ECO	17	68	76	50	15	✓	22,76 €
G4-18/ECO	18	72	80	50	15	✓	24,22 €
G4-19/ECO	19	76	84	60	15	✓	24,86 €
G4-20/ECO	20	80	88	60	15	✓	26,69 €
G4-21/ECO	21	84	92	70	20	✓	27,86 €
G4-22/ECO	22	88	96	70	20	✓	30,44 €
G4-23/ECO	23	92	100	75	20	✓	33,89 €
G4-24/ECO	24	96	104	75	20	✓	35,96 €
G4-25/ECO	25	100	108	75	20	✓	37,97 €
G4-26/ECO	26	104	112	75	20	✓	40,40 €
G4-27/ECO	27	108	116	75	20	✓	44,59 €
G4-28/ECO	28	112	120	75	20	✓	47,21 €
G4-29/ECO	29	116	124	75	20	✓	48,78 €
G4-30/ECO	30	120	128	75	20	✓	51,82 €
G4-31/ECO	31	124	132	80	20	✓	52,91 €
G4-32/ECO	32	128	136	80	20	✓	54,76 €
G4-33/ECO	33	132	140	80	20	✓	57,43 €
G4-34/ECO	34	136	144	80	20	✓	60,03 €
G4-35/ECO	35	140	148	80	20	✓	62,60 €
G4-36/ECO	36	144	152	80	20	✓	70,74 €

Dimensions in mm

 Our other products



CAB

Galvanised steel cable, Galvanised steel



PNR

Reflector support,



GMK17_R

Round guide, Round guide for conical profile



DOMI50

Accessories, Clamping lever



INO

Internal gear, Steel 20NCD2



PP35

Worm and wheel gear reducer, from 2.20 to 4.10 Nm



EAR

Bearing locknut, Self locking locknut - nylon lock washer



DER80

Stainless steel AC asynchronous motor 0.55 - 0.75kW, 0.55 to 0.75kW



ACM_TRI

Manual bonnet fastener, Black rubber



UGH32

H Type Guide units, For Ø32 actuators



VPRA_M

 
Handwheel with handle,



MEB

Moulded plastic bevel gear (nylon), 1:1

Complementary products



MR_MMR

Metric section rack, Steel



G4

Steel spur gear, Steel 20NCD2



ZG4

Plastic spur gear, Machined plastic (delrin)



YG4

HEAVY DUTY spur gear, Steel 35NCD6