

GA6 GA8

Fixed force, 50 to 400N


- Gas spring
- Works in compression (push) mode
- Operating fluid: Gas (Nitrogen) and oil
- Materials:
 - Rod: Chrome-plated steel
 - Body: Steel
 - Rod end: Nylon
- Spring must be mounted with piston pointing down
- Size 6: from 50N to 400N
- Size 8: from 100N to 540N



Supplied with nylon end

Uses

- Opening of bonnets or boots
- Saves effort

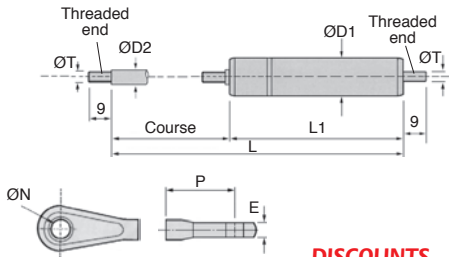

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	List	-10%	-15%	-20%	On request

Part number	Stroke (mm)	L (mm)	L1 (mm)	ØD1 (mm)	ØD2 (mm)	ØT (mm)	ØN (mm)	P (mm)	E (mm)	Oil zone length (mm)	Force (N)	Stock*	Price each 1 to 5
Size 6													
GA6060050	60	160	100	15	6	M5	6	17	8	20	50	✓	115,52 €
GA6100080	100	240	140	15	6	M5	6	17	8	20	80	✓	116,20 €
GA6150100	150	340	190	15	6	M5	6	17	8	20	100	✓	116,20 €
GA6200200	200	440	240	15	6	M5	6	17	8	20	200	-	119,06 €
Size 8													
GA8100100	100	264	164	18	8	M6	8	21	10	30	100	✓	126,43 €
GA8150200	150	364	214	18	8	M6	8	21	10	30	200	✓	128,31 €
GA8200300	200	464	264	18	8	M6	8	21	10	30	300	✓	130,55 €
GA8250400	250	564	314	18	8	M6	8	21	10	30	400	✓	132,48 €

*Depending on availability - Dimensions in mm

Our other products



PPC55
Pad eye on mounting
plate squarred,
Stainless steel



DCG
Suction cup, 2.5
bellows, nitrile



PRF_BR
Clamp for aluminium
profile, Clamp for
profile



EHD12
Internal epicyclic
servo reducers, from
60 to 140 Nm



PVL
Small lobed handle,
Polyamide



HLU55
Spoked handwheel,
Stainless steel 316



CHM40
Worm and wheel gear
reducer, up to 57 Nm



F7-SF-SM
Multifunction display,
Mounting bracket for
front mounting



PSG055
Spur gear - precision
range, Stainless steel
316



M1
Worm and wheel set,
Bronze



WFRM
Flanged polymer nut,
Polymer (Iglidur®) - 1
thread



MEFC
Flanged sintered
ferrous bush, Self-
lubricating FP20
ferrous alloy M...

Complementary products



CLR
Straight clevis,
Straight clevis for use
with a male clevis



GSI
Stainless steel gas
spring, Stainless steel



RAS
90° ball and socket
joints DIN71802, Steel



IBJ
180° ball and socket
joints, Steel