




Force adjustable up to 650N

GA6A
GA8A

- **Gas spring**
- **Works in compression (push) mode**
- Operating fluid: Gas (Nitrogen) and oil
- Materials:
 - Rod: Chrome-plated steel
 - Body: Steel
 - Rod end: Nylon
- Size 6: from 50N to 400N
- Size 8: from 100N to 540N
- Spring must be mounted with piston pointing down
- Adjustment: Gas should be released using the valve to achieve the force required.




   **Supplied with
nylon end**



Uses

- Opening of bonnets or boots
- Saves effort

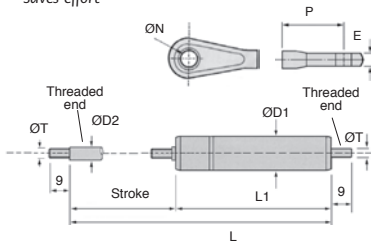

**These springs
cannot be refilled,
never allow all of
the gas to escape.**

DISCOUNTS

Qty.	1+	6+	10+	15+	20+
Disc.	List	-10%	-15%	-20%	On request

Part number	Stroke (mm)	L (mm)	L1 (mm)	ØD1 (mm)	ØD2 (mm)	ØT (mm)	ØN (mm)	P (mm)	E (mm)	Oil zone length (mm)	Force (N)	Stock*	Price each 1 to 5
Size 6													
GA6060A	60	160	95	15	6	M5	6	17	8	20	50-400	✓	115,52 €
GA6100A	100	240	135	15	6	M5	6	17	8	20	80-400	✓	116,20 €
GA6150A	150	340	185	15	6	M5	6	17	8	20	100-400	✓	116,20 €
GA6200A	200	440	235	15	6	M5	6	17	8	20	200-400	✓	119,06 €
Size 8													
GA8100A	100	264	159	18	8	M6	8	21	10	30	100-650	✓	126,43 €
GA8150A	150	364	209	18	8	M6	8	21	10	30	100-650	✓	128,31 €
GA8200A	200	464	259	18	8	M6	8	21	10	30	100-650	✓	130,55 €
GA8250A	250	564	309	18	8	M6	8	21	10	30	100-650	✓	132,48 €

*Depending on availability - Dimensions in mm

Our other products



CHA1056_U4
Screw-in hinge,
Section 40X40



P30
Worm and wheel gear
reducer, up to 8.80
Nm




YG1
HEAVY DUTY spur
gear, Steel 35NCD6



GE32
Sprung toggle latch
with connecting link,
Standard



UCFL_PBT
Stainless
steel/Polymer flanged
bearing, Polymer and
stainless steel

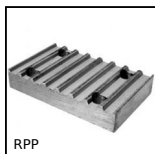

RPP
Connecting plate for
RPP type timing belts,
RPP14



KGS
Ballscrew, supplied by
the metre, Rolled
ballscrew, per metre



SRG
Adjustable latch
clamp with strike
plate, Stroke from
117,4mm to 128mm



MDB_MTB
Moulded plastic bevel
gear (nylon), 3:1



PRF4590
Standard aluminium
profile, 45 x 90 mm



MET
Cylindrical sintered
bronze bush, Self-
lubricating sintered



CHMR75
Worm and wheel gear
reducer, up to 298
Nm

Complementary products



CLR
Straight clevis,
Straight clevis for use
with a male clevis



GSI_A
Stainless steel
adjustable gas spring,
Stainless steel



CLM
Male clevis end, Steel
short



RAS
90°ball and socket
joints DIN71802, Steel