

# Latch clamp with lock

 
 




## GAC

## Lockable

- Snap closing
- Supplied with 2 identical keys
- Latch clamp and strike plates supplied separately
- Material:  
Galvanised steel

### Advantage

- Can be locked using a key

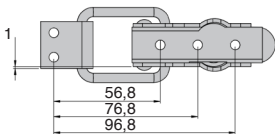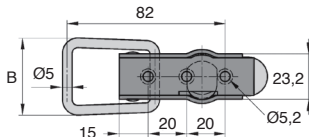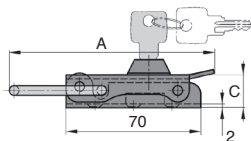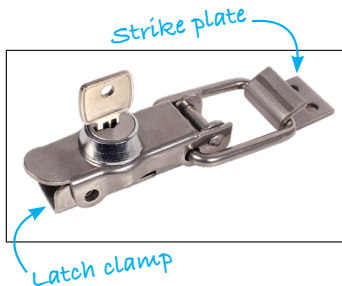

Hole layout

### DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc	List	-3%	-5%	-10%	On request

Part number	Material	Finish	A	B	C	D	E	Weight (g)	Price each	
									Stock*	1 to 9
<b>Latch clamp</b>										
GAC-106	steel	Galvanized	106,5	40,0	17,0	-	-	132	✓	17,94 €
<b>Strike plate</b>										
GAC-106G	steel	Galvanized	-	-	-	28	25	24	✓	3,81 €

\*Depending on availability - Dimensions in mm

## Our other products



HLUss

Spoked handwheel,  
Stainless steel 316



BTCW

Cap for square tube to  
be welded, To be  
welded



ADL\_F

Female eye bolt  
conforms to DIN582,  
Stainless steel



MRA

Quick link, Steel



HTD14M\_85

HTD Heavy duty  
timing pulley, HTD14  
Steel



OP6

Mechanical digital  
position indicator, 5  
numbers



ZG4

Plastic spur gear,  
Machined plastic  
(delrin)



CNA-CNG

Right angled  
mounting plate, Right  
angled mounting  
plate for ball jo...



AFA

Locking pin, with ring



SSB

Stainless steel bevel  
gear, 1:1



BLHB30

Right angled gearbox,  
bored shafts, up to  
4.47 Nm



PCF2

Conical flexible  
mount, Oval base  
plate

## Complementary products




GAC

Lock for latch clamp,  
Strike plate



GE

Toggle latches,  
Standard

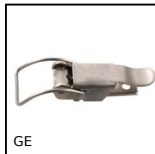

GE

Toggle latches,  
Standard



SVG

Adjustable latch  
clamp with strike  
plate, Stroke from  
82mm to 92mm