

# Latch clamp with lock

 
 




## GAC

## Lockable

- Snap closing
- Supplied with 2 identical keys
- Latch clamp and strike plates supplied separately
- Material:  
Galvanised steel

### Advantage

- Can be locked using a key

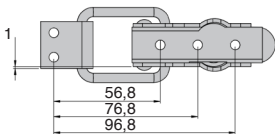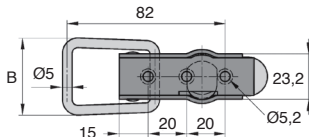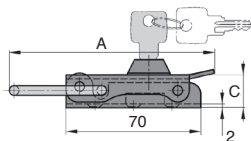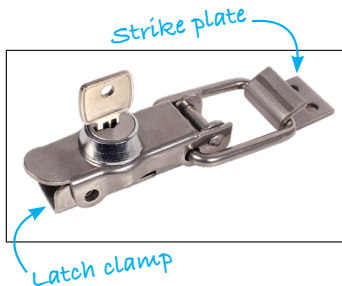

Hole layout

### DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc	List	-3%	-5%	-10%	On request

Part number	Material	Finish	A	B	C	D	E	Weight (g)	Price each
									Stock*
<b>Latch clamp</b>									
GAC-106	steel	Galvanized	106,5	40,0	17,0	-	-	132	✓ 17,94 €
<b>Strike plate</b>									
GAC-106G	steel	Galvanized	-	-	-	28	25	24	✓ 3,81 €

\*Depending on availability - Dimensions in mm

## Our other products



HK

Manual locking clamp,  
Manual locking clamp  
LRX



PRF\_FIX\_STD

Fastener for  
aluminium profile,  
Standard fastener



DOMI50

Accessories, Plate



NPR

Reflector support,



PW\_PWG15

Worm - precision  
range, Steel



CHN\_CHNSS

Straight long link  
chain, Galvanised  
steel



RHTplss

High Temperature  
Castor, up to 200kg



 
VML

Stainless steel  
hexagonal headed  
thumb screw, Male



PSG125HC

Skive hobbed spur  
gears - precision  
range, Case hardened



CTss

Universal joint,  
telescopic, Inox, Light  
duty



MDB\_MTB

Moulded plastic bevel  
gear (nylon), 2:1



PRF\_BASE

Base plate for  
aluminium profile,  
Base plate

## Complementary products



GAC

Latch clamp with lock,  
Lockable