

# Decorative rigid latch clamp

## GAE

 

## With or without key

- **Snap closing**
- Supplied with 2 identical keys for the key versions
- Supplied with catch plate
- **Material:**  
Die cast zinc black coating

**NEW!**



With or without key

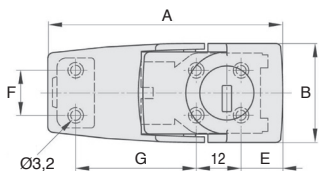

### DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-3%	-5%	On request

Part number	A	B	C	E	F	G	Weight (g)	Price each 1 to 9
<b>Without key</b>								
GAE17-64	64,5	26,5	17,3	13	12	30	72	
GAE21-76	76	32	21	16,8	16	35,5	118	
<b>With key</b>								
GAE17-64/K	64,5	26,5	17,3	13	12	30	72	
GAE21-76/K	76	32	21	16,8	16	35,5	118	

Dimensions in mm


## Our other products




CHAGC-AL  
Screw-in garnet hinge, Screw-on



PRF\_ART  
Articulated bracket for use with aluminium profile, With clamping ha...

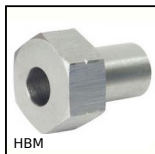

HBM  
Adjustment bushing for half-rail guide, Adjustment bushing

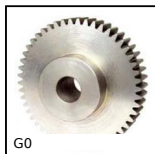


G0  
Steel spur gear, Steel 20NCD2



MHX  
Hexagonal threaded sleeve, Hexagonal - steel



M0  
Wormwheel, Bronze

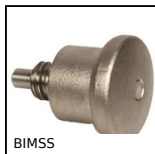

BIMSS  
Indexing plunger mini, miniature - Stainless steel



AT5P\_AT10P  
Connecting plate for AT type timing belts, AT10



DCA  
Suction cup, 1.5 bellows, nitrile



GB-RA  
Brass spur gear, Brass CuZn39Pb3



CABtool  
Fitting cable tools, Crimping tools



CHT  
Asynchronous AC Motor, 0.18 to 0.55kW

## Complementary products



GEC  
Rubber latch clamp with strike plate, Lockable



GE  
Toggle latches, Miniature



GE14  
Toggle latches, With padlock-holder



GE32  
Sprung toggle latch with connecting link, Standard