

Conveyor wheel



GAL22



Zinc plated steel


- **Load capacity:** 100N static, 200N dynamic
- Turns on a single row of balls
- **Materials:**
roller: zinc plated steel
bearings: steel balls on zinc plated steel hub

Info.

- Not sold individually, please contact us for details

Advantages

- Smooth rotation
- Treated steel hub for long life expectancy.

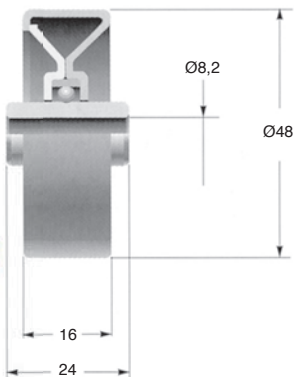

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Static load (N)	Dynamic load (N)	Stock*	Price each 1 to 49
GAL22-01	100	200	✓	3,66 €


*Depending on availability - Dimensions in mm

Our other products



ZG0

 Plastic spur gear,
Machined plastic
(delrin)



BMF

Knurled knob -
female, Knurled -
through threaded



PRF45_GOU

Chute profile,
Accessories



PRS50

Stainless steel
articulated foot Ø50,
Ø 50



E50

Right angle helical
reducers, from 3 to 41
Nm



TBD

Manual leadscrew
table with opposing
threads, 40kg



RPCTcss

Swivel castor with
central hole, Stainless
steel - Polyamide -
with ...



UTKpawr

Utilitrak® 3 wheels
carriage, Polymer
roller carriage



CLQassortiment

Assorted feeler strips,
Assorted feeler strips



HG5

Steel spur gear, Steel
20NCD2



M1

Worm and wheel set,
Hardened steel



BKGS

Backlash free
coupling Gerwah®,
from 1.2 to 450Nm

Complementary products



GAL21

Conveyor wheel,
Plastic