

# Conveyor wheel



## GAL22



## Zinc plated steel


- **Load capacity:** 100N static, 200N dynamic
- Turns on a single row of balls
- **Materials:**  
roller: zinc plated steel  
bearings: steel balls on zinc plated steel hub

### Info.

- Not sold individually, please contact us for details

### Advantages

- Smooth rotation
- Treated steel hub for long life expectancy.

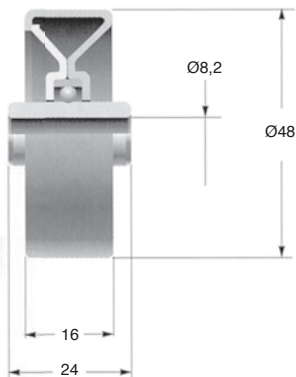

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number | Static load (N) | Dynamic load (N) | Stock* | Price each<br>1 to 49 |
|-------------|-----------------|------------------|--------|-----------------------|
| GAL22-01    | 100             | 200              | ✓      | 3,66 €                |

\*Depending on availability - Dimensions in mm

## Our other products



BAC105

Storage bin, 8mm



NSU

Universal 90° support clamp, Universal 90° support clamp



PWC

Powercoil thread inserts, Kit Powercoil - with or without insertion ...



 
PCS\_PA6

Plastic sprocket, 12.7mm (DIN 08B-1)



BHC

Socket head button screw, Stainless steel A2



SLS

Bearing block for leadscrew, Floating Drylin® bearing block



PRF\_T

Corner reinforcement, Corner reinforcement



SKM

Hexagonal steel nut, Steel - 1 thread



HTD8M\_50

HTD Heavy duty timing pulley, HTD8 Steel



TOC

Short swivel head, Short



DIV\_SS

Stainless steel locking bolt, With grip - Stainless steel



SVG

Adjustable latch clamp with strike plate, Stroke from 82mm to 92mm

## Complementary products



GAL21

Conveyor wheel, Plastic