

# Conveyor wheel



## GAL22



## Zinc plated steel


- **Load capacity:** 100N static, 200N dynamic
- Turns on a single row of balls
- **Materials:**  
roller: zinc plated steel  
bearings: steel balls on zinc plated steel hub

### Info.

- Not sold individually, please contact us for details

### Advantages

- Smooth rotation
- Treated steel hub for long life expectancy.

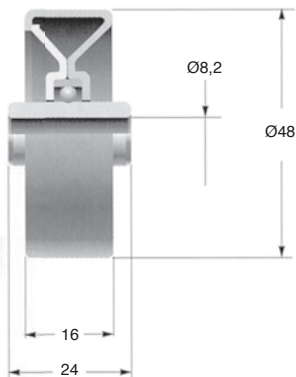

### DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Static load (N)	Dynamic load (N)	Stock*	Price each 1 to 49
GAL22-01	100	200	✓	3,66 €

\*Depending on availability - Dimensions in mm

## Our other products



HTD5M\_09

HTD Heavy duty timing pulley, HTD5 Aluminium



CHM40-MOT

Asynchronous AC motorgearboxes 0.18 to 0.55kW, 0.18 to 0.55kW



GCL

Linear ball slide Eco Range, economy range



CHV

Mechanical speed variator, from 0,18 to 1,5kW



BPVM

Miniature ball transfer unit, Miniature to screw



RFK48B

Hypoid gearbox - Stainless steel, up to 350 Nm



GSI\_A

Gas control screw for gas spring, Gas control screw



SBF

Sealed flange bearing unit for Food Industry, cover



PCLA\_M

Technopolymer clamping lever -



G-ECO

Eco range Spur gear, Steel C45



LFM2

Steel leadscrew, Medium carbon steel -



YG1

HEAVY DUTY spur gear, Steel 35NCD6

## Complementary products



GAL21

Conveyor wheel, Plastic