

Force adjustable up to 650N

**GA6A**  
**GA8A**

 
 
 


- Gas spring
- Works in compression (push) mode
- Operating fluid: Gas (Nitrogen) and oil
- Materials:
  - Rod: Chrome-plated steel
  - Body: Steel
  - Rod end: Nylon
- Size 6: from 50N to 400N
- Size 8: from 100N to 540N
- Spring must be mounted with piston pointing down
- Adjustment: Gas should be released using the valve to achieve the force required.



**Supplied with nylon end**

## Uses

- Opening of bonnets or boots
- Saves effort

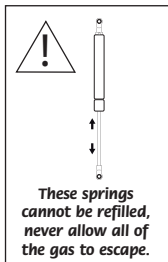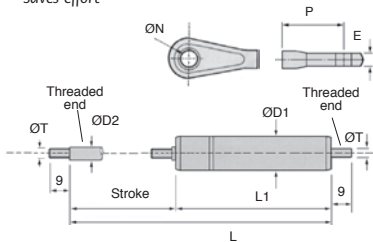

## DISCOUNTS

Qty.	1+	6+	10+	15+	20+
Disc.	List	-10%	-15%	-20%	On request

Part number	Stroke (mm)	L (mm)	L1 (mm)	ØD1 (mm)	ØD2 (mm)	ØT (mm)	ØN (mm)	P (mm)	E (mm)	Oil zone length (mm)	Force (N)	Stock*	Price each 1 to 5
<b>Size 6</b>													
GA6060A	60	160	95	15	6	M5	6	17	8	20	50-400	✓	115,52 €
GA6100A	100	240	135	15	6	M5	6	17	8	20	80-400	✓	116,20 €
GA6150A	150	340	185	15	6	M5	6	17	8	20	100-400	✓	116,20 €
GA6200A	200	440	235	15	6	M5	6	17	8	20	200-400	✓	119,06 €
<b>Size 8</b>													
GA8100A	100	264	159	18	8	M6	8	21	10	30	100-650	✓	126,43 €
GA8150A	150	364	209	18	8	M6	8	21	10	30	100-650	✓	128,31 €
GA8200A	200	464	259	18	8	M6	8	21	10	30	100-650	✓	130,55 €
GA8250A	250	564	309	18	8	M6	8	21	10	30	100-650	✓	132,48 €

\*Depending on availability - Dimensions in mm

## Our other products



RFK58C  
Hypoid gearbox -  
Stainless steel, up to  
500 Nm



RDE-B  
Sealing washer  
Hygienic Usit®,  
Stainless steel - Blue  
EPDM



PX  
Optional output shaft  
stainless steel, P  
gearboxes single  
sided outp...



BPH  
Ball transfer unit plain  
fit, High



PTA100  
Articulated levelling  
foot, pressed base  
Ø100, Ø 100



AFA  
Locking pin, with ring



MEB  
Moulded plastic bevel  
gear (nylon), 1:1



RHTplss  
High Temperature  
Castor, up to 200kg




AT10-25ECO  
AT type timing pulley,  
Economy range -  
AT10 aluminium



VTA  
Vari-Tork® slip  
friction clutch, 0.53 to  
1.32 Nm



 CHM30  
Worm and wheel gear  
reducer, up to 28 Nm



RPPM  
RPP type belt per  
metre, RPP8 Steel  
cored polyurethane

## Complementary products



CLR  
Straight clevis,  
Straight clevis for use  
with a male clevis



GA  
Gas spring, Steel



GSI\_A  
Stainless steel  
adjustable gas spring,  
Stainless steel



CLM  
Male clevis end, Steel  
short