


- Nut for ballscrew
- Multiple starts
- Axial backlash: 0.2mm
- Material:  
16 MnCr5 or 100Cr6

### Accessory

- See KGS ballscrew (the pitch and the diameter must be identical to those of the nut)

GBM nut

Multiple starts

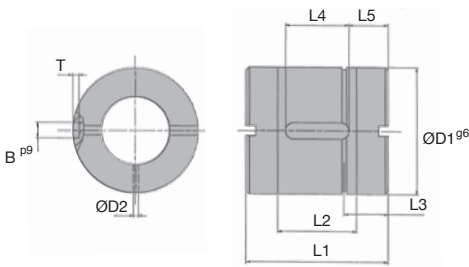

### DISCOUNTS

Qty	1+	2+	6+	11+
Disc.	List	-7%	-13%	On request

Part number	ØD1g6	ØD2	L1	L2	L3	L4	L5	BxT
GBM-Z-2020-RH	35	1,5	30	14	11,50	12	9	5x3
GBM-Z-2050-RH	35	1,5	56	40	14	20	18	5x2
GBM-Z-3220-RH	53	1,5	55	35	16	20	17,5	6x4
GBM-Z-3240-RH	53	1,5	50	30	16	25	12,5	6x4
GBM-Z-5020-RH	85	1,5	73,50	50	16,75	30	22	6x2,5

Part number	For screw Ø	Movement per rev (mm)	Load		Weight (kg)	Price each
			dynamic C (kN)	static Co (kN)		
GBM-Z-2020-RH	20	20	9,00	19,10	0,15	445,63 €
GBM-Z-2050-RH	20	50	7,90	19,00	0,30	487,14 €
GBM-Z-3220-RH	32	20	19,50	65,00	0,50	595,84 €
GBM-Z-3240-RH	32	40	11,50	33,50	0,45	598,93 €
GBM-Z-5020-RH	50	20	61,70	178,40	1,40	1060,26 €

\*Subject to available stock - Dimensions in mm

## Our other products




Ball pin socket, Socket



Spur gear - precision range, Case hardened steel 20NCD2



Swaging sleeve for fitting cable, To crimp a wire rope

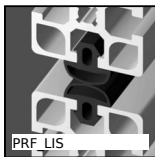

Door seal for aluminium profile, Black NBR



T type timing pulley, Economy range - T5 aluminium



Hinge without pin, Plastic hinge



Manual workbench press, Force up to 500kg



Adjustable cross clamp, Adjustable



Combined bearing with inner ring, Axial load in one direction



Multifunction display, With external sensor




Roller for aluminium profile, Fixing kit for roller concentric



Spur gear coaxial gearbox, from 10 to 35 Nm - In-line

## Complementary products

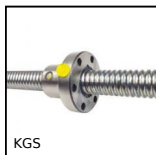

Ballscrew, supplied by the metre, Rolled ballscrew, per metre