


- Nut for ballscrew
- Multiple starts
- Axial backlash: 0.2mm
- Material:
16 MnCr5 or 100Cr6

Accessory

- See KGS ballscrew (the pitch and the diameter must be identical to those of the nut)

GBM nut

Multiple starts

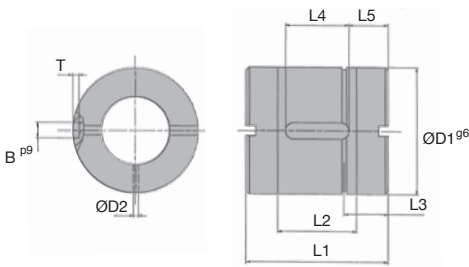

DISCOUNTS

Qty	1+	2+	6+	11+
Disc.	List	-7%	-13%	On request

Part number	ØD1g6	ØD2	L1	L2	L3	L4	L5	BxT
GBM-Z-2020-RH	35	1,5	30	14	11,50	12	9	5x3
GBM-Z-2050-RH	35	1,5	56	40	14	20	18	5x2
GBM-Z-3220-RH	53	1,5	55	35	16	20	17,5	6x4
GBM-Z-3240-RH	53	1,5	50	30	16	25	12,5	6x4
GBM-Z-5020-RH	85	1,5	73,50	50	16,75	30	22	6x2,5

Part number	For screw Ø	Movement per rev (mm)	Load		Weight (kg)	Price each
			dynamic C (kN)	static Co (kN)		
GBM-Z-2020-RH	20	20	9,00	19,10	0,15	445,63 €
GBM-Z-2050-RH	20	50	7,90	19,00	0,30	487,14 €
GBM-Z-3220-RH	32	20	19,50	65,00	0,50	595,84 €
GBM-Z-3240-RH	32	40	11,50	33,50	0,45	598,93 €
GBM-Z-5020-RH	50	20	61,70	178,40	1,40	1060,26 €

*Subject to available stock - Dimensions in mm

Our other products



DOMI120

Domino 120 adjustable slide, Slide DOMILINE 120



F7-P-AM

Multifunction display, Magnetic band



AC

Strike for toggle latch, 15mm



YG2

HEAVY DUTY spur gear, Steel 35NCD6



SUPccss

Self-centering clamping hub stainless steel, With lock nut



LACT_SS

Adjustable Stainless steel cam lever, Male



RPP

Connecting plate for RPP type timing belts, RRP5



TBE16

Economic mini-table with trapezoidal leadscrew, 5kg



DIV_SS

Stainless steel locking bolt, With grip -



GLB

Small 6 lobe threaded handle - female,



SEH

 
Horizontal stirrup toggle clamp,



G01

Single universal joint, Normal duty

Complementary products



KGS

Ballscrew, supplied by the metre, Rolled ballscrew, per metre