



- Nut for ballscrew
- Axial backlash:  
0.05mm for a 5mm pitch  
0.1mm for a 10mm pitch
- Material: Steel MnCr5 or 100Cr6

### Accessories

- See KGS screw

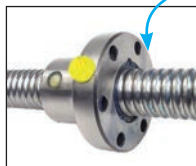

Extended range,  
new sizes available

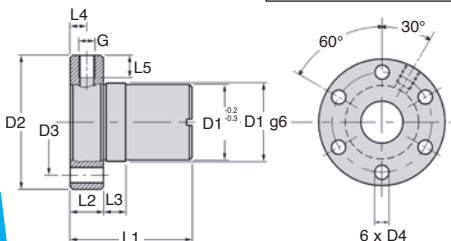

### DISCOUNTS


Qty	1+	2+	6+	11+
Disc. List	-7%	-13%		On request

Part number	D1 g6	D2 h13	D3	D4	L1	L2	L3	L4	L5	G
GBS-F-1605-RH	28	48	38	5,5	44	12	8	6	8	M6
GBS-F-2005-RH	32	55	45	7,0	44	12	8	6	8	M6
GBS-F-2505-RH	38	62	50	7,0	46	14	8	7	8	M6
GBS-F-3205-RH	45	70	58	7,0	59	16	10	8	8	M6
GBS-F-3210-RH	53	80	68	7,0	73	16	10	8	8	M8 x 1
GBS-F-4005-RH	53	80	68	7,0	59	16	10	8	8	M6
GBS-F-4010-RH	63	95	78	9,0	73	16	10	8	8	M8 x 1

Part number	For screw Ø	Movement per turn (mm)	dynamic C (kN)	Load static Co (kN)	Weight (kg)	Stock*	Price each
GBS-F-1605-RH	16	5	7,0	12,7	0,20	✓	203,75 €
GBS-F-2005-RH	20	5	7,0	17,0	0,25	✓	207,78 €
GBS-F-2505-RH	25	5	9,5	22,4	0,35	✓	253,43 €
GBS-F-3205-RH	32	5	17,0	49,0	0,55	✓	334,00 €
GBS-F-3210-RH	32	10	25,7	56,0	0,90	✓	348,06 €
GBS-F-4005-RH	40	5	19,0	63,5	0,80	✓	337,41 €
GBS-F-4010-RH	40	10	30,0	70,0	1,20	-	399,02 €

\*Depending on availability - Dimensions in mm

## Our other products

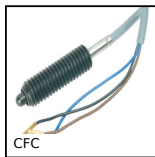

CFC

Spring loaded position switch, Electric contact



BLH50

Right angled gearbox, from 7.70 to 20 Nm



PRF\_PSA

Shaft support for aluminium profile, Linear guide shaft



DCA

Suction cup, 1.5 bellows, silicon



RRP

Connecting plate for RPP type timing belts, RRP5



BLHM70

Right angled gearbox, up to 128 Nm




TBEBASE10

Economic mini-table with trapezoidal lead screw, 1kg



TSRTC

 Stem support for caster, For swivel caster with central hole



RPPM

RPP type belt per metre, RPP5 Steel cored polyurethane



PRF\_JL5

Lip seal for panel, Door seal - Ø 5mm



CHAC4040SS


Square hinge with riveted pin, drilled, Square with riveted



PRES7HR

Manual workbench press, Force up to 700kg

## Complementary products

 

KGS

Ballscrew, supplied by the metre, Rolled ballscrew, per metre



BSB

Ballscrew bearing unit, Support



GBSsz

Cylindrical ballscrew nut, Cylindrical lead screw nut