



- Nut for ballscrew
- Axial backlash:  
0.05mm for a 5mm pitch  
0.1mm for a 10mm pitch
- Material: Steel MnCr5 or 100Cr6

### Accessories

- See KGS screw

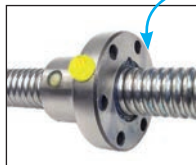

Extended range,  
new sizes available

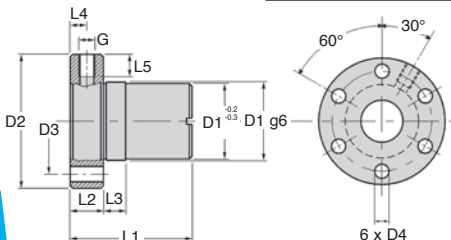

### DISCOUNTS

Qty	1+	2+	6+	11+
Disc.	List	-7%	-13%	On request

Part number	D1 g6	D2 h13	D3	D4	L1	L2	L3	L4	L5	G
GBS-F-1605-RH	28	48	38	5,5	44	12	8	6	8	M6
GBS-F-2005-RH	32	55	45	7,0	44	12	8	6	8	M6
GBS-F-2505-RH	38	62	50	7,0	46	14	8	7	8	M6
GBS-F-3205-RH	45	70	58	7,0	59	16	10	8	8	M6
GBS-F-3210-RH	53	80	68	7,0	73	16	10	8	8	M8 x 1
GBS-F-4005-RH	53	80	68	7,0	59	16	10	8	8	M6
GBS-F-4010-RH	63	95	78	9,0	73	16	10	8	8	M8 x 1

Part number	For screw Ø	Movement per turn (mm)	dynamic C (kN)	Load static Co (kN)	Weight (kg)	Stock*	Price each
GBS-F-1605-RH	16	5	7,0	12,7	0,20	✓	203,75 €
GBS-F-2005-RH	20	5	7,0	17,0	0,25	✓	207,78 €
GBS-F-2505-RH	25	5	9,5	22,4	0,35	✓	253,43 €
GBS-F-3205-RH	32	5	17,0	49,0	0,55	✓	334,00 €
GBS-F-3210-RH	32	10	25,7	56,0	0,90	✓	348,06 €
GBS-F-4005-RH	40	5	19,0	63,5	0,80	✓	337,41 €
GBS-F-4010-RH	40	10	30,0	70,0	1,20	-	399,02 €


\*Depending on availability - Dimensions in mm

## Our other products



LVT

Miniature motorised actuator 4A, 4 ampers

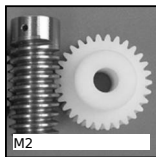

M2

Worm and wheel set, Machined plastic (delrin)



NSR

Adjustable clamp, Adjustable



CAP882

Flexible slat top chain acetal, Large range 882



WJUM20

Drylin® W bearing block, Slide



ETQ

Magnetic label holder for aluminium profile, Label holder



BOXdh

Boxed set of cylindrical dowel pins DIN6325, Boxed set - Solid DIN 6...



PRES7HR

Manual workbench press, Force up to 700kg



BOX-TOR-ORFS

Box set of Nitrile O-rings NBR90Sh A, 7.65 x 1.78mm to 37.82 x



AT10-25ECO

AT type timing pulley, Economy range - AT10 aluminium



PPG

Indexing plunger with flange, With horizontal mounting



CHA225

Screwed hinge with threaded insert, 225 degrees

## Complementary products



KGS

Ballscrew, supplied by the metre, Rolled ballscrew, per metre



BSB

Ballscrew bearing unit, Support



GBSz

Cylindrical ballscrew nut, Cylindrical leadscrew nut