
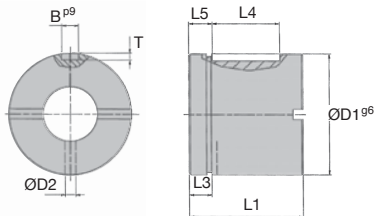


- Nut for use with a Ballscrew
- Axial backlash: 0.05 mm for screws with 5mm pitch 0.1 mm for screws with 5mm pitch
- Material:  
16 MnCr5 or 100 Cr6

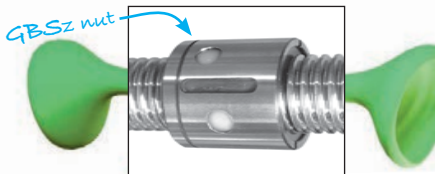

### Accessories

- Please see the **KGS** ball screw  
The pitch and diameter must be the same as that of the nut)

### DISCOUNTS

Qty	1+	2+	6+	11+
Disc.	List	-7%	-13%	On request

Part number	ØD1 <sup>96</sup>	ØD2	L1	L3	L4	L5	BxT
GBS-Z-2005-RH	32	3	34	6,75	20	7	5x2
GBS-Z-2505-RH	38	3	34	6,75	20	7	5x2
GBS-Z-3205-RH	45	3	45	7,25	30	7,5	6x2,5
GBS-Z-3210-RH	53	3	60	10	30	15	6x2,5
GBS-Z-4005-RH	53	3	45	7,25	30	7,5	6x2,5
GBS-Z-5010-RH	72	4	82	11	36	23	6x2,5
GBS-Z-6310-RH	85	4	82	11	36	23	6x2,5

Part number	For screw		Load		Weight (kg)	Price each
	Ø	Travel per revolution (mm)	dynamic C (kN)	static Co (kN)		
GBS-Z-2005-RH	20	5	8,00	17,00	0,15	170,24 €
GBS-Z-2505-RH	25	5	9,50	22,40	0,20	194,14 €
GBS-Z-3205-RH	32	5	17,00	49,00	0,30	275,75 €
GBS-Z-3210-RH	32	10	25,70	56,00	0,60	324,98 €
GBS-Z-4005-RH	40	5	19,00	63,50	0,50	347,76 €
GBS-Z-5010-RH	50	10	55,00	153,00	1,10	453,87 €
GBS-Z-6310-RH	63	10	60,00	200,00	1,50	766,00 €

Dimensions in mm

## Our other products



T5M T10M

T type timing belt per metre, T5 Steel cored polyurethane



KB\_OP

Open precision linear bearing, Precision - steel



SH2

Parallel axis helical gear, Machined plastic (delrin)



 
PGR

Folding revolving handle for handwheel, Folding



R203

Die spring ISO10243, Light



RPP8

RPP heavy duty timing belt, RPP8



PGB

Accessory-holder for aluminium profile, Tool holder



PRF3232

Standard aluminium profile, 32 x 32 mm




CHA135

Screwed hinge, 135 degrees



BTSS

 Universal stainless steel arm for



M0

Worm and wheel set, Machined plastic



LVT

Miniatur motorised actuator 1A, 1 amper

## Complementary products



KGS

Ballscrew, supplied by the metre, Rolled ballscrew, per metre



GBS

Nut for ballscrew, Flanged ballscrew nut