

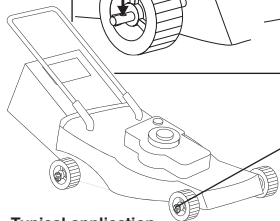


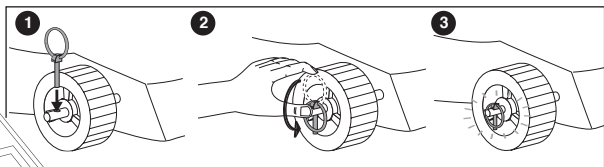

- Low cost clip
- Made from zinc plated steel
- Supplied by the packet

### Advantages

- Manual assembly/disassembly

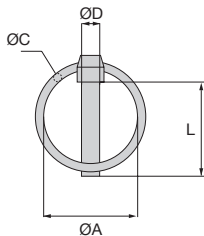

Typical application

**INCREASED STOCK**

### DISCOUNTS

Qty	1+	5+	10+	21+
Disc.	List	-10%	-20%	On request

Part number	ØD	L	ØA	ØC	Weight per 100 (kg)	Quantity per pack	Stock*	Price each 1 to 4
GCA4.5-3/B	4,5	42	34	3	1,31	100	✓	42,50 €
GCA6-3.5/B	6	42	41	3,5	2,30	50	✓	21,86 €
GCA7-3.5/B	7	42	41	3,5	2,65	50	✓	22,21 €
GCA8-3.5/B	8	42	41	3,5	2,91	50	✓	25,66 €
GCA9-3.5/B	9	42	41	3,5	3,55	50	-	27,65 €
GCA10-3.5/B	10	42	41	3,5	4,27	50	✓	29,03 €
GCA11-3.5/B	11	42	41	3,5	4,77	50	-	30,46 €

\*Depending on availability - Dimensions in mm

## Our other products



PR125  
Articulated foot  $\varnothing 123$ ,  
 $\varnothing 123$



CHA\_GC\_9SS  
Stainless steel garnet  
hinge, To be welded



F7-I  
Multifunction display,  
With internal sensor



BSCm  
Knurled torque knobs  
- male, Knurled  
threaded torque



BABam  
Self-locking ball pin  
lifting ring for  
threaded hole, Self-  
locking



STL  
Guidance brush - Rail,  
Rail



PSG125HC  
Skive hobbed spur  
gears - precision  
range, Case hardened  
steel 20NCD2



GGP  
Male wing knob,  
Technopolymer with  
brass spindle



NDS20  
Double cross clamp,  
Parallel



PR105  
Articulated foot  $\varnothing 103$ ,  
 $\varnothing 103$



TOC  
Short swivel head,  
Short



F7-P-AM  
Multifunction display,  
Magnetic band

## Complementary products



GCT  
Pipe linch pin, Tube  
linch pin



AFA  
Locking pin, with ring