

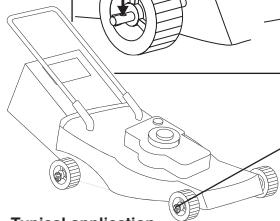


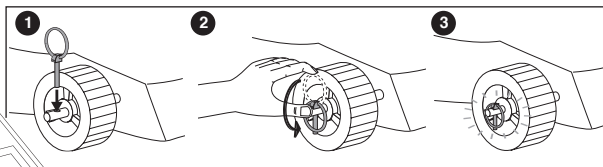

- Low cost clip
- Made from zinc plated steel
- Supplied by the packet

Advantages

- Manual assembly/disassembly

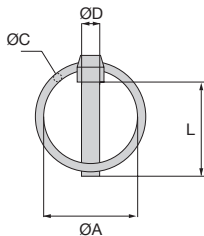

Typical application

INCREASED STOCK

DISCOUNTS

Qty	1+	5+	10+	21+
Disc.	List	-10%	-20%	On request

Part number	ØD	L	ØA	ØC	Weight per 100 (kg)	Quantity per pack	Stock*	Price each 1 to 4
GCA4.5-3/B	4,5	42	34	3	1,31	100	✓	42,50 €
GCA6-3.5/B	6	42	41	3,5	2,30	50	✓	21,86 €
GCA7-3.5/B	7	42	41	3,5	2,65	50	✓	22,21 €
GCA8-3.5/B	8	42	41	3,5	2,91	50	✓	25,66 €
GCA9-3.5/B	9	42	41	3,5	3,55	50	-	27,65 €
GCA10-3.5/B	10	42	41	3,5	4,27	50	✓	29,03 €
GCA11-3.5/B	11	42	41	3,5	4,77	50	-	30,46 €

*Depending on availability - Dimensions in mm

Our other products



FUSS

Bearing locknut, Self locking locknut - stainless steel lock washer



CTZYSS

Stainless steel diablo shaped elasto mount, Stainless steel



 
KITdog

24V DC motorisation kit, Worm and wheel



PRES7HR

Manual workbench press, Force up to 700kg



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings, Extraction tools



PRF4545_P

Stripp Aluminium profile with extendable slot, 45 x 45 mm



HSSss

Stainless steel shoulder screw ISO7379, Stainless steel ISO 7379




HW_HT

Half-rail guide, Rail



PCS37K

 Chain sprocket with hardened teeth,



JSM

Cylindrical polymer bush, Universal



SBF

Open flange bearing unit for food industry,



GP

Spring loaded toggle latch, Standard

Complementary products



GCT

Pipe linch pin, Tube linch pin



AFA

Locking pin, with ring