



Curved track for plate chain


For chain ranges
880 TAB and 881 TAB

GCB880T

- Used to support and guide CAP880T and CAP881T/SS plate chains
- Material
High density Black DESLIDUR

Info.

- Comprises 2 tracks (carry and return)

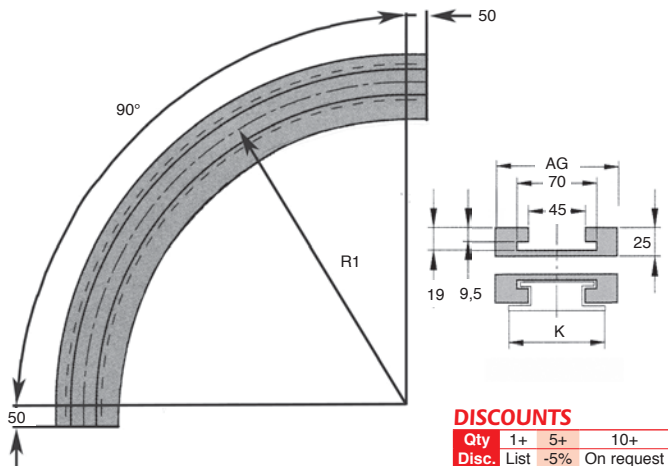

DISCOUNTS

Qty	1+	5+	10+
Disc. List	-5%	On request	

Part number	For chain	AG (mm)	R1 (mm)	K (mm)	Weight (kg)	Price each 1 to 4
GCB880T-82	CAP880T-82 CAP881T-82/SS	100	500	82,5	2,4	142,36 €
GCB880T-114	CAP880T-114 CAP881T-114/SS	130	610	114,3	4,4	276,47 €

Dimensions in mm

Our other products



T10_21_AL

T type timing pulley,
Economy range - T10
aluminium



PLA

Flat magnet, Flat
magnet with thread



SBF

Open flange bearing
unit for food industry,
cover



MEB

Moulded plastic bevel
gear (nylon), 1:1



BPTR

End cap for round
tube, Standard



RPC

Wheel, Polyamide



SERB

Cam latch, Cam latch



GAL22

Conveyor wheel, Zinc
plated steel



BOXdhx

Boxed set of threaded
dowel pins DIN7979D,
Boxed set -



TRMSS

Spur round rack,
Stainless steel -
module 1-5



G4-ECO

Eco range Spur gear,
Steel C45



MBF

Threaded blocking
clamp, Threaded
locking clamp

Complementary products



CAP880

Side flexing slim slat
top chain acetal,
Narrow range 880



CAP881

Side flexing slim slat
top chain stainless
steel, Narrow range
881



SDG

Adjustable guide
support bracket,
Plastic