



Curved track for plate chain


For chain ranges
880 TAB and 881 TAB

GCB880T

- Used to support and guide CAP880T and CAP881T/SS plate chains
- Material
High density Black DESLIDUR

Info.

- Comprises 2 tracks (carry and return)

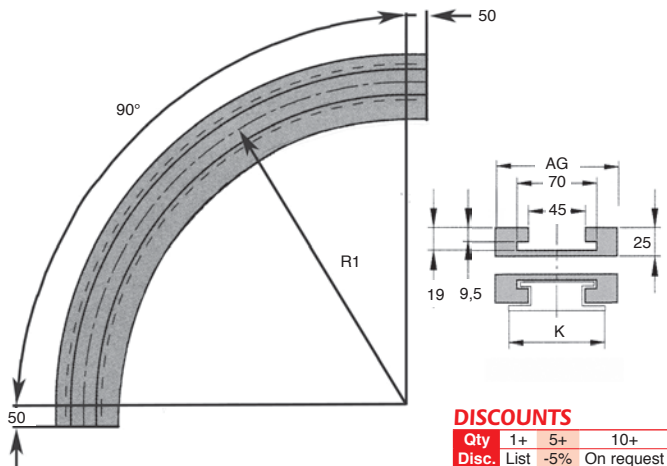

DISCOUNTS

Qty	1+	5+	10+
Disc. List	-5%	On request	

Part number	For chain	AG (mm)	R1 (mm)	K (mm)	Weight (kg)	Price each 1 to 4
GCB880T-82	CAP880T-82 CAP881T-82/SS	100	500	82,5	2,4	142,36 €
GCB880T-114	CAP880T-114 CAP881T-114/SS	130	610	114,3	4,4	276,47 €

Dimensions in mm

Our other products



SH1

Parallel axis helical gear, Machined plastic (delrin)



GCH

Linear ball slide - Stainless steel balls, Chariot - from 514 N to 1...



PM3

Worm and wheel set, Hardened steel



PLC_PLT

Magnetic stud with threaded hole, With threaded hole



RJA10_03

Sealing strip, Clipping



RPCplss

Fixed castor with plate, Stainless steel - Polyamide



PRF_FIX_ANG

Fastener for aluminium profile, Angular joint



SUPss

Self-centering clamping hub stainless steel, Without locknut



HTD5M_25

HTD Heavy duty timing pulley, HTD5 Aluminium



BOXbeta

Box of assorted hitch pins, Boxed set - hitch



BAGSS

Stainless steel Clamping collar, Stainless steel



M2

Worm and wheel set, Machined plastic (delrin)

Complementary products



CAP880

Side flexing slim slat top chain acetal, Narrow range 880



CAP881

Side flexing slim slat top chain stainless steel, Narrow range 881



SDG

Adjustable guide support bracket, Plastic