
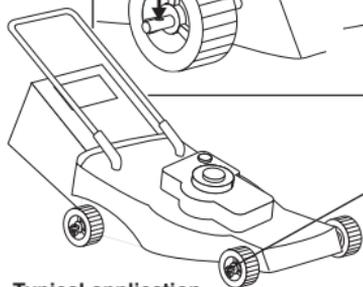
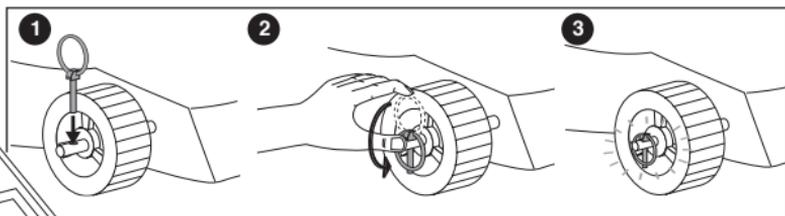


- Low cost clip
- Made from zinc dichromate steel
- Supplied by the packet

Advantages

- Manual assembly/disassembly

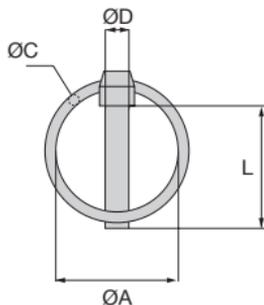

Typical application

DISCOUNTS

Qty	1+	5+	10+	21+
Disc.	List	-10%	-20%	On request





Part number	ØD	L	ØA	ØC	Weight per 100 (kg)	Quantity per pack	Stock*	Price each 1 to 4
GCA4.5-3/B	4,5	42	34	3	1,31	100	✓	42,50 €
GCA6-3.5/B	6	42	41	3,5	2,30	50	✓	21,86 €
GCA7-3.5/B	7	42	41	3,5	2,65	50	✓	22,21 €
GCA8-3.5/B	8	42	41	3,5	2,91	50	✓	25,66 €
GCA9-3.5/B	9	42	41	3,5	3,55	50	-	27,65 €
GCA10-3.5/B	10	42	41	3,5	4,27	50	✓	29,03 €
GCA11-3.5/B	11	42	41	3,5	4,77	50	-	30,46 €

*Depending on availability - Dimensions in mm

- Low cost clip
- Made from zinc dichromate steel
- Supplied by the packet

Advantages

- Manual assembly/disassembly

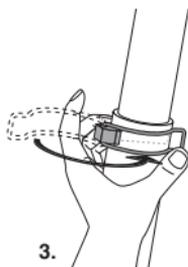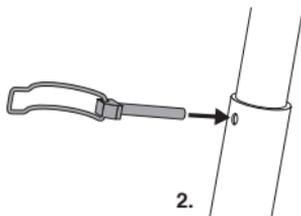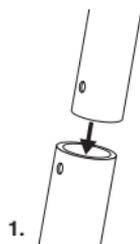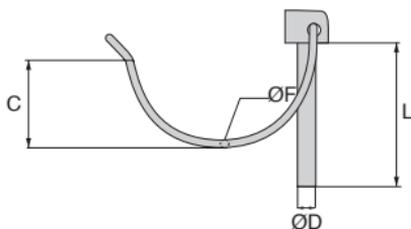

DISCOUNTS

Qty	1+	5+	10+	21+
Disc.	List	-10%	-20%	On request

Part number	ØD	L	C	ØF	For tube ØT	Weight per 100 (kg)	Qty per packet	Stock*	Price each 1 to 4
GCT4.5-40/B	4,5	40	18	3	38-39	1,7	50	✓	31,90 €
GCT6-32/B	6	32	18	3	30-31	2,0	50	✓	34,01 €
GCT6-45/B	6	45	22	3	43-44	2,6	50	✓	36,78 €
GCT8-40/B	8	40	18	3	38-39	3,5	50	✓	40,32 €
GCT8-45/B	8	45	22	3	43-44	3,8	50	✓	43,06 €
GCT8-50/B	8	50	25	3	48-49	4,0	50	✓	45,72 €
GCT8-60/B	8	60	28	3	58-59	4,3	50	✓	49,93 €
GCT10-40/B	10	40	18	3,2	37-38	5,0	25	✓	27,22 €
GCT10-50/B	10	50	25	3,2	47-48	5,8	25	✓	30,21 €
GCT10-60/B	10	60	28	3,2	57-58	6,3	25	✓	33,52 €

*Depending on availability - Dimensions in mm