



Pipe linch pin

 

Zinc plated steel

GCT


- Low cost clip
- Made from white zinc plated steel
- Supplied by the packet

Advantages


- Manual assembly/disassembly

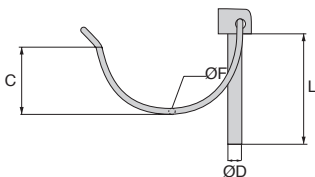

1.

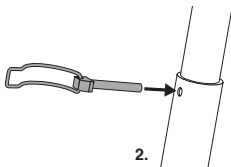

2.

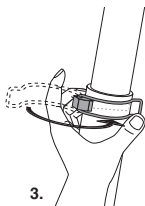

3.



4.



DISCOUNTS

Qty	1+	5+	10+	21+
Disc.	List	-10%	-20%	On request

Part number	ØD	L	C	ØF	For tube ØT	Weight per 100 (kg)	Qty per packet	Stock*	Price each 1 to 4
GCT4.5-40/B	4,5	40	18	3	38-39	1,7	50	✓	27,00 €
GCT6-32/B	6	32	18	3	30-31	2,0	50	✓	28,77 €
GCT6-45/B	6	45	22	3	43-44	2,6	50	✓	31,11 €
GCT8-40/B	8	40	18	3	38-39	3,5	50	✓	34,09 €
GCT8-45/B	8	45	22	3	43-44	3,8	50	✓	36,41 €
GCT8-50/B	8	50	25	3	48-49	4,0	50	✓	38,65 €
GCT8-60/B	8	60	28	3	58-59	4,3	50	✓	42,23 €
GCT10-40/B	10	40	18	3,2	37-38	5,0	25	✓	23,03 €
GCT10-50/B	10	50	25	3,2	47-48	5,8	25	✓	25,56 €
GCT10-60/B	10	60	28	3,2	57-58	6,3	25	✓	28,36 €

*Depending on availability - Dimensions in mm

Our other products



PF45
Worm and wheel gear reducer, up to 40 Nm



Q1
Self-aligning radial ball bearing, Steel



CHB
Worm and wheel gear reducer, up to 41 Nm



F7-P-AM
Multifunction display, Magnetic ring



MSP23
Masterplate® glueable insert Ø23, Cylindrical Ø23 with tapped ins...



VCMB
Dual-thread screw wood/metal, Stainless steel



DER71
Stainless steel AC asynchronous motor 0.25 à 0.37kW, 0.25 to 0.37kW



 
FBL4004_K7
Brush strip per meter PA6 fibres Ø0.3 to Ø0.5, Black polyamide 6 -...



GE
Toggle latches, Standard



PFM
Fixed levelling foot, Flanged plate



IN2
Internal gear, Machined plastic (delrin)



SSG1
Stainless steel spur gear, Stainless steel 304L

Complementary products



GCA
Linch pin, Linch



AFA
Locking pin, with ring