

Straight track for plate chain




GDR880T

For chain ranges
880 TAB and 881 TAB

- Used to support and guide CAP880T and CAP881T/
SS plate chains
- Material:
Black DESLIDUR

Info.

- Comprises 2000mm tracks (carry and return)

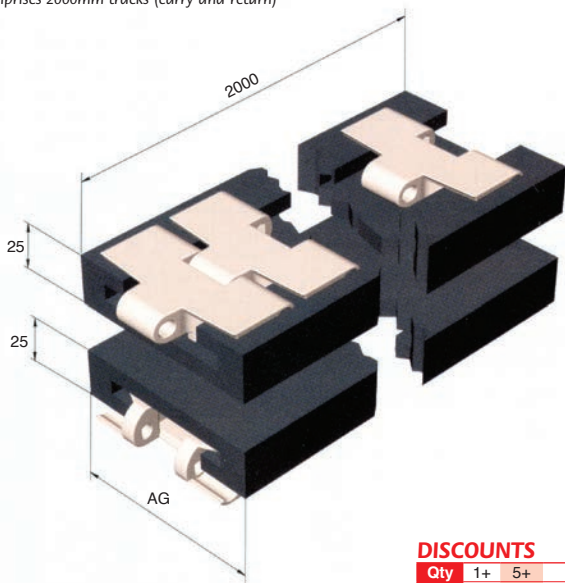

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	For chain	AG (mm)	Length (mm)	Weight (kg)	Price each 1 to 4
GDR880T-82	CAP880T-82 CAP881T-82/SS	100	2000	5,9	266,45 €
GDR880T-114	CAP880T-114 CAP881T-114/SS	130	2000	8,8	345,92 €

Dimensions in mm

Our other products



BPHRF

Ball transfer unit
housed spring loaded,
High



IBjss

Ball and socket joint,
Stainless steel



RPCtc

Swivel castor with
central hole, Steel -
Polyamide



SBF

Sealed flange bearing
unit for Food Industry,
cover



CLG2

Moulded plastic spur
gear, Moulded plastic
(nylon)



SHW

Plain washer, A2
Stainless steel



MET

Cylindrical sintered
bronze bush, Self-
lubricating sintered
bronze



VELM4

Screw-on base for
hook-and-loop strip,
Polyamide



AF

Shaft clamp with
keyway, Set screw



SSB

Stainless steel bevel
gear, 1:1



ACLEPP

Right angled bracket
for aluminium profile,



SH4

Parallel axis helical
gear, Steel 20NCD2

Complementary products



CAP880

Side flexing slim slat
top chain acetal,
Narrow range 880




CAP881

Side flexing slim slat
top chain stainless
steel, Narrow range
881



SDG

 Adjustable guide
support bracket,
Plastic



GMC

Flat profile - Round
guide, Flat profile -
round guide