



Straight track for plate chain

For chain range 882 TAB

GDR882T


- Used to support and guide CAP882T and CAP881T/SS plate chains

- Material:

Black DESLIDUR

Info.

- Comprises 2000mm tracks (carry and return)

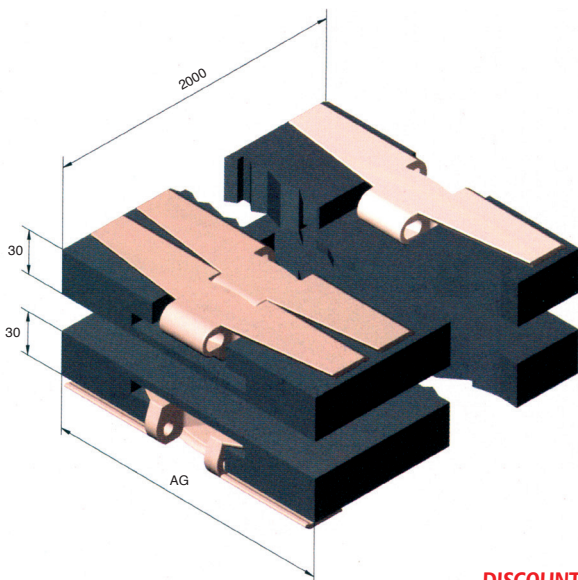

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	For chain	AG (mm)	Length (mm)	Weight (kg)	Price each 1 to 4
GDR882T-190	CAP882T-190	200	2000	17,3	439,18 €
GDR882T-254	CAP882T-254	270	2000	25,4	580,08 €
GDR882T-304	CAP882T-304	320	2000	31,3	658,17 €

Dimensions in mm

Our other products



SH0
Parallel axis helical gear, Machined plastic (delrin)



DB_ECO
Eco. range steel bevel gear, 2:1



GD01
Double universal joint, Standard duty



J64
Spur gear coaxial gearbox, from 0.57 to 2.25 Nm - Inline



EMS
Stainless steel knurled thumb nut, Knurled




DSF
Slip friction clutch, 4 to 2600 Nm




SSB
Stainless steel bevel gear, 1:1



 AT5-10ECO
AT type timing pulley, Economy range - AT5 aluminium



IN2
Internal gear, Machined plastic

 

PF15
Worm and wheel gear reducer, up to 3,75



PP60
Worm and wheel gear reducer, from 17.80



CFS
Miniature cam follower, Miniature

Complementary products



CAP882
Flexible slat top chain acetal, Large range 882



PR882
Idler sprocket for slat top chain, Range 882