

GE5 GE18

Standard and miniature versions

- Hook fastening

- Material:

White zinc steel or stainless steel 303

Assembly

- GE5-ZB and GE5-SS are used with AC121-ZB and AC121-SS hooks, dimension X = 77.5mm to withstand a tension up to 350N
- GE18-ZB and GE18-SS are used with AC118-ZB and AC118-SS hooks, dimension X = 31.1mm to withstand a tension up to 150N
- Dimension X taken on the first hole of the hook.

Advantages

- Very flexible



Info.

- Not sold individually, please contact us for details

Accessories

- Hooks AC121, AC118 (t.imagetome1 p.125)

steel or stainless steel

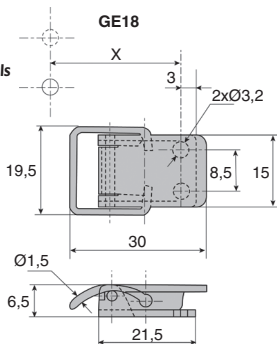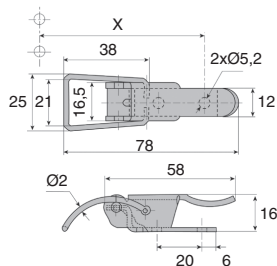

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Material	Wire Ø	Lever thickness mm	Back-plate thickness	Max. tension (N)	Weight (g)	Stock*	Price each 1 to 50
Standard								
GE5-ZB	steel	2,0	20/10th	20/10th	500	36,0	✓	3,24 €
GE5-SS	stainless steel	2,0	20/10th	20/10th	500	36,0	✓	6,55 €
Miniature								
GE18-ZB	steel	1,5	8/10th	10/10th	300	6,5	✓	1,92 €
GE18-SS	stainless steel	1,5	8/10th	10/10th	300	6,5	✓	3,10 €

*Subject to availability - Dimensions in mm

Our other products



S4

Chain sprocket-
stainless steel, 4mm



BAN

Angular clamp,
Adjustable



PRS100

Stainless steel
articulated foot Ø100,
Ø 100



YG1

HEAVY DUTY spur
gear, Steel 35NCD6



CHCSS

Socket headed screw,
Stainless steel - A2



 
P55

Worm and wheel gear
reducer, up to 57 Nm



BAGSS

Stainless steel
Clamping collar,
Stainless steel



PF20NM

Worm and wheel gear
reducer, up to 5 Nm



HSE-HSB

Hexagonal spacer,
Steel



SCH

Horizontal hook
toggle clamp,



BOX-TOR-INCH

Box set of Nitrile O-
rings in inch NBR90Sh



CHC

Socket headed screw,
Steel class 12.19

Complementary products



GP75

Spring loaded toggle
latch, Standard
(GP75)



GE32

Sprung toggle latch
with connecting link,
Standard