

GE5 GE18

Standard and miniature versions

- Hook fastening

- Material:

White zinc steel or stainless steel 303

Assembly

- GE5-ZB and GE5-SS are used with AC121-ZB and AC121-SS hooks, dimension X = 77.5mm to withstand a tension up to 350N
- GE18-ZB and GE18-SS are used with AC118-ZB and AC118-SS hooks, dimension X = 31.1mm to withstand a tension up to 150N
- Dimension X taken on the first hole of the hook.

Advantages

- Very flexible



Info.

- Not sold individually, please contact us for details

Accessories

- Hooks AC121, AC118 (t.imagetome1 p.125)

steel or stainless steel

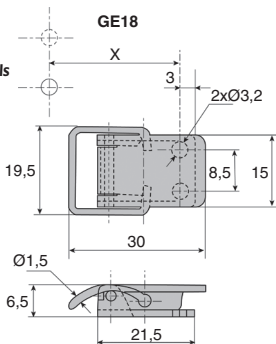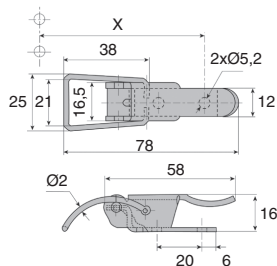

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Material	Wire Ø	Lever thickness mm	Back-plate thickness	Max. tension (N)	Weight (g)	Stock*	Price each 1 to 50
Standard								
GE5-ZB	steel	2,0	20/10th	20/10th	500	36,0	✓	3,24 €
GE5-SS	stainless steel	2,0	20/10th	20/10th	500	36,0	✓	6,55 €
Miniature								
GE18-ZB	steel	1,5	8/10th	10/10th	300	6,5	✓	1,92 €
GE18-SS	stainless steel	1,5	8/10th	10/10th	300	6,5	✓	3,10 €

*Subject to availability - Dimensions in mm

Our other products



PFC
Fixed rubber leveling foot, Levelling support for small parts



AC144
Strike for toggle latch, 22mm



 
AT5P_AT10P
Connecting plate for AT type timing belts, AT10



RTN
BoWex® curved tooth gear coupling, Nylon



BFDdII
Locking pin for bushes, Nickel-plated steel



M0
Worm and wheel set, Machined plastic (delrin)



F7-I
Multifunction display, With internal sensor



MDB_MTB
Moulded plastic bevel gear (nylon), 2:1



NK27
Drylin®N miniature guiding system, Width



PNA_R
PERIFLEX elastic coupling,



GAC
Latch clamp with lock, Lockable



UTKpwrr
V shaped channel UtiliTrak®, V rail

Complementary products



AC
Strike for toggle latch, 12,13,18 and 20mm



GEC
Rubber latch clamp with strike plate, Lockable



GAC
Latch clamp with lock, Lockable