

Flexible toggle latch

Stock StaSte

GE1006

Slot fastening

- Hook fastening
- Ring is slightly flexible
- Material: White zinc steel or stainless steel 303

Steel or stainless steel






Assembly

- Approx mounting dimension:
X = 56.6mm to withstand a tension of 400N

Info

- Not sold individually, please contact us for details

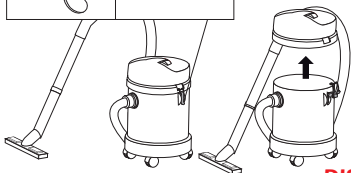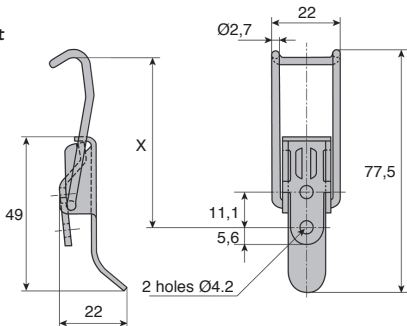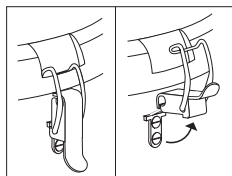

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Wire Ø	Lever thickness	Back-plate thickness	Max. Tension (N)	Weight (g)	Stock*	Price each 1 to 50
GE1006-ZB	2,7	15/10th	20/10th	550	25	✓	1,76 €
Stainless steel							
GE1006-SS	2,5	15/10th	20/10th	550	24	✓	8,46 €

*Subject to availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



BPLF

Ball transfer unit light duty, Light



RCX-6

Spherical tilt washer - DIN6319, concave



P70

Worm and wheel gear reducer, up to 164 Nm



SNG

Stainless/Polymer pillow block bearing, Cast iron - Split pillow



HSE-HSB

Hexagonal spacer, Steel



BFD

Locking pin for bush, +180°C



GCL

Linear ball slide - Stainless steel balls, Chariot - from 516 N to 8...



PRF_FIX_ANG

Fastener for aluminium profile, Angular joint



GAL22

Conveyor wheel, Zinc plated steel



CAP820

Slim slat top chain acetal, Narrow



PSPD40

Flexible tube handle, Black PVC



PRF_JL5

Lip seal for panel, Door seal - Ø 5mm

Complementary products



GP75

Spring loaded toggle latch, Standard (GP75)



GE32

Sprung toggle latch with connecting link, Standard