

- Hook fastening
- Material: White zinc steel

### Assembly




- GE14-ZB is used with AC101-ZB hook, dimension X = 53.9mm to withstand a tension up to 350N

### Advantages

- Flexible positioning
- Can be operated many times without loss of clamping force
- Extended tolerance on positioning

### Info.

- Not sold individually, please contact us for details

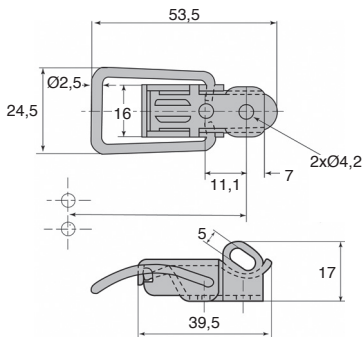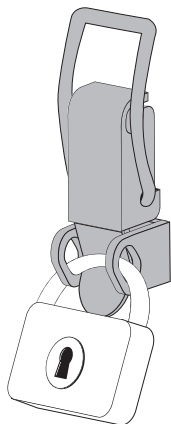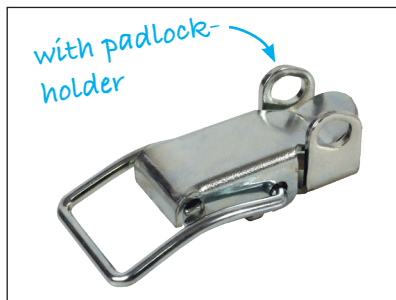

### DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Wire Ø	Lever thickness	Back-plate thickness	Max. tension (N)	Weight (g)	Stock*	Price each 1 to 50
GE14-ZB	2,5	15/10th	2mm	500	21,9	✓	3,39 €

\*Subject to availability - Dimensions in mm

## Our other products



Bracket for aluminium profile, PRF4590



Spherical tilt washer - DIN6319, concave



Right angled gearbox, bored shafts, up to 10.3 Nm



Weld-on hinge with flat end, Steel



Storage bin, 8mm



HEAVY DUTY spur gear, Steel 35NCD6




Deep groove ball bearing, Steel



Male eye bolt conforms to DIN580, Steel



Support rod for heavy loads, Support spindle

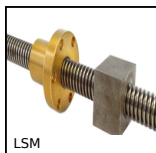

Stainless steel 316L leadscrew, Stainless



Short swivel head, Short



Worm and wheel set, Hardened steel


## Complementary products




Strike for toggle latch, 15mm



Strike for toggle latch, 15mm

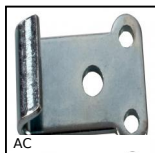

Strike for toggle latch, 15mm

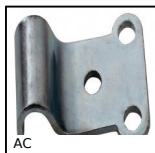

Strike for toggle latch, 15mm