

- Hook fastening
- Material: White zinc steel

### Assembly




- GE14-ZB is used with AC101-ZB hook, dimension X = 53.9mm to withstand a tension up to 350N

### Advantages

- Flexible positioning
- Can be operated many times without loss of clamping force
- Extended tolerance on positioning

### Info.

- Not sold individually, please contact us for details

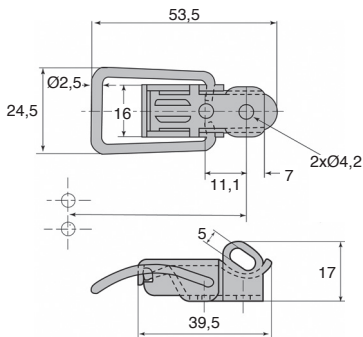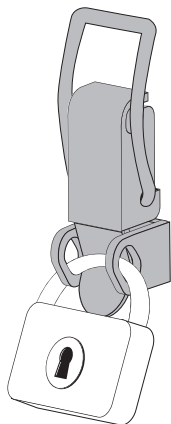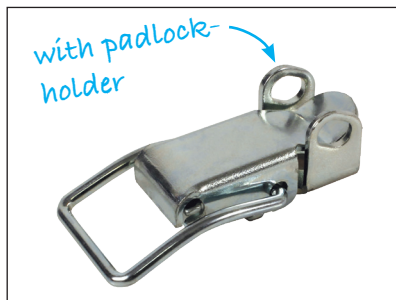

### DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Wire Ø	Lever thickness	Back-plate thickness	Max. tension (N)	Weight (g)	Stock*	Price each 1 to 50
GE14-ZB	2,5	15/10th	2mm	500	21,9	✓	3,39 €

\*Subject to availability - Dimensions in mm

## Our other products



BOX-SHNA

Hexagonal nut -  
DIN934, Box set of  
steel nuts



RCC\_RCX

Spherical tilt washer -  
DIN6319, convex



DER80

Stainless steel AC  
asynchronous motor  
0.55 - 0.75kW, 0.55 to  
0.75kW



 
ZBconique

Machined plastic  
bevel gear, 1:1



PRF\_JL5

Lip seal for panel,  
Door seal - Ø 5mm



Q3

Double row angular  
contact ball bearing,  
Angular contact -  
Steel



LRR-53

Spring loaded latch,  
Spring return latch -  
stainless steel



M1

Worm and wheel set,  
Machined plastic  
(delrin)




PRF4590\_E

Bracket for aluminium  
profile, PRF4590



PF45

 Worm and wheel gear  
reducer, up to 40 Nm



LAT2


2A motorised linear  
actuator, 2 amperes



M0

Worm and wheel set,  
Hardened steel

## Complementary products

 


AC

Strike for toggle latch,  
15mm




AC

 Strike for toggle latch,  
15mm



AC

Strike for toggle latch,  
15mm

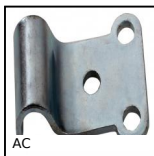

AC

Strike for toggle latch,  
15mm