

GE1006

Slot fastening

- Hook fastening
- Ring is slightly flexible
- Material:
White zinc steel or stainless steel 303

Steel or stainless steel






Assembly

- Approx mounting dimension:
X = 56.6mm to withstand a tension of 400N

Info.

- Not sold individually, please contact us for details

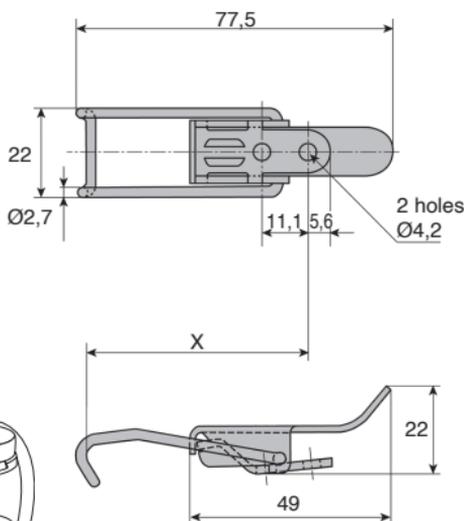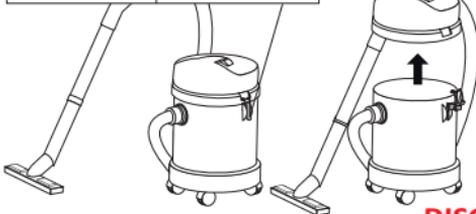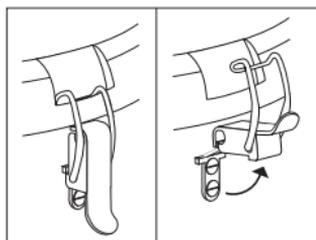

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Wire Ø	Lever thickness	Back-plate thickness	Max. Tension (N)	Weight (g)	Stock*	Price each 1 to 50
Steel							
GE1006-ZB	2,7	15/10th	20/10th	550	25	✓	2,00 €
Stainless steel							
GE1006-SS	2,5	15/10th	20/10th	550	24	✓	9,58 €

*Subject to availability - Dimensions in mm

Standard and miniature versions

**GE5
GE18**

- Hook fastening
- Material:
White zinc steel or stainless steel 303

Assembly

- **GE5-ZB** and **GE5-SS** are used with **AC121-ZB** and **AC121-SS** hooks, dimension X = 77.5mm to withstand a tension up to 350N
- **GE18-ZB** and **GE18-SS** are used with **AC118-ZB** and **AC118-SS** hooks, dimension X = 31.1mm to withstand a tension up to 150N
- Dimension X taken on the first hole of the hook.

Advantages

- Very flexible



Info.

- Not sold individually, please contact us for details

Accessories

- Hooks **AC121**, **AC118** (tome 1 p.174)

steel or stainless steel

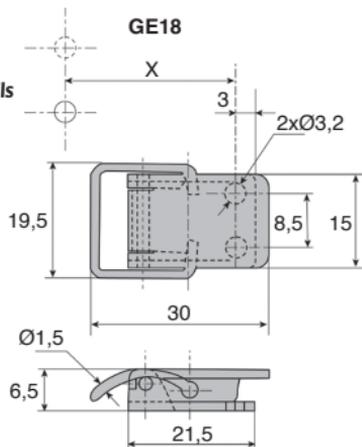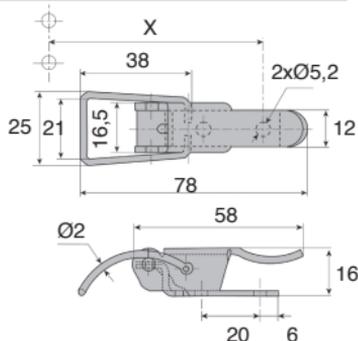

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Material	wireØ	Lever thickness mm	Back-plate thickness	Max tension (N)	Weight (g)	Stock*	Price each 1 to 50
Standard								
GE5-ZB	steel	2,0	20/10th	20/10th	500	36,0	✓	3,64 €
GE5-SS	stainless steel	2,0	20/10th	20/10th	500	36,0	✓	7,35 €
Miniature								
GE18-ZB	steel	1,5	8/10th	10/10th	300	6,5	✓	2,15 €
GE18-SS	stainless steel	1,5	8/10th	10/10th	300	6,5	✓	3,47 €

*Subject to availability - Dimensions in mm

- Hook fastening
- Material:
White zinc steel

Assembly

- GE14-ZB is used with AC101-ZB hook, dimension X = 53.9mm to withstand a tension up to 350N
- Dimension X taken on the first hole of the hook.

Advantages




- Flexible positioning
- Can be operated many times without loss of clamping force
- Extended tolerance on positioning

Info.

- Not sold individually, please contact us for details

Accessory

- Hooks AC101 (tome 1 p.173)

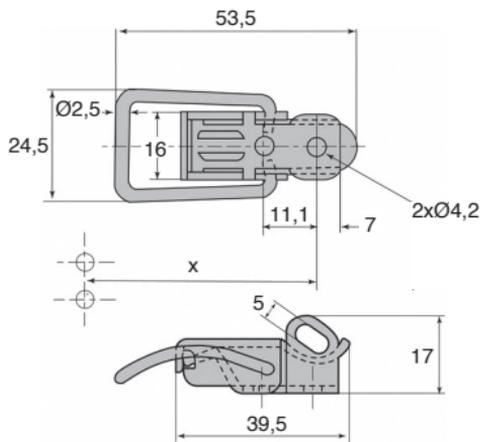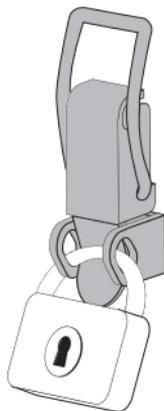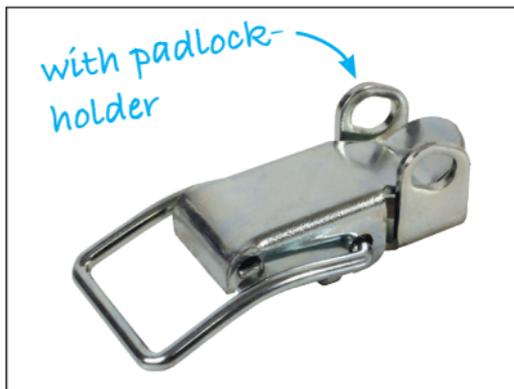

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Wire Ø	Lever thickness	Back-plate thickness	Max. tension (N)	Weight (g)	Stock*	Price each 1 to 50
GE14-ZB	2,5	15/10th	2mm	500	21,9	✓	3,84 €

*Subject to availability - Dimensions in mm

Widths: 12, 13, 18 and 20mm

ACZB
ACSS

- Hook fastening
- Material:
White zinc steel or stainless steel 303


Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

Info.

- Not sold individually, please contact us for details

steel or stainless steel

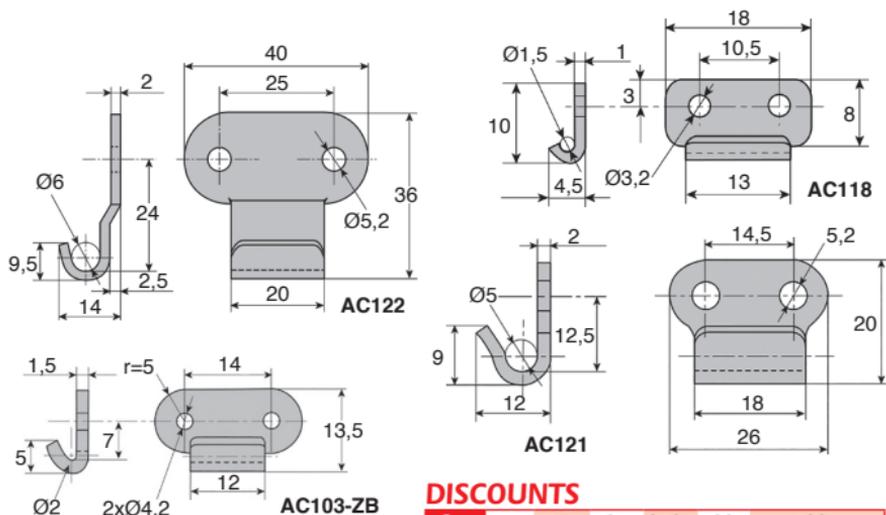

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Steel				
AC103-ZB	-	3,4	-	0,30 €
AC118-ZB	GE18-ZB	1,5	✓	0,22 €
AC121-ZB	GE5-ZB	9,4	✓	0,49 €
AC122-ZB	GP22-ZB and GP23-ZB	1,9	✓	0,93 €
Stainless steel				
AC118-SS	GE18-SS	1,5	✓	0,45 €
AC121-SS	GE5-SS	9,4	✓	1,33 €
AC122-SS	GP22-SS and GP23-SS	1,9	✓	2,60 €

*Subject to availability - Dimensions in mm

Hook for latch



ACZB
ACss

15mm wide versions

- Hook fastening
- Material:

White zinc steel or stainless steel 303

steel or stainless steel







Selection

- Choose your own hook/latch combination by simply verifying the interior width of the ring and selecting a hook with a smaller width

Info.

- Not sold individually, please contact us for details

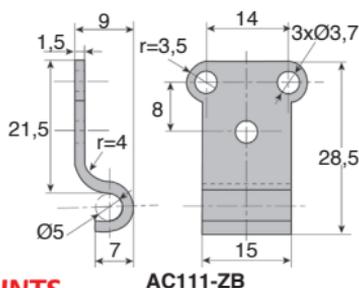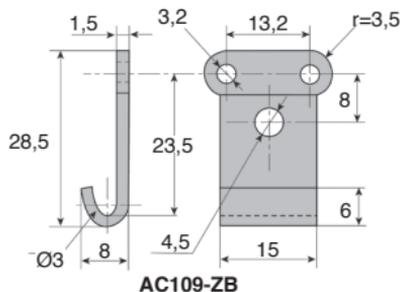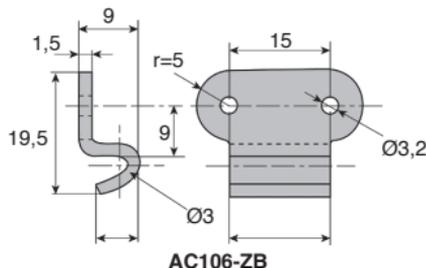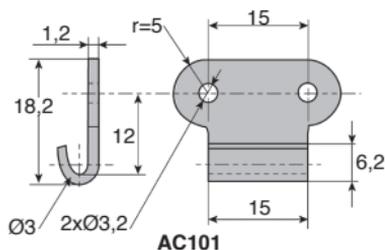

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Steel				
AC101-ZB	GE14-ZB	4,7	✓	0,68 €
AC106-ZB	GE14-ZB	5,2	✓	1,08 €
AC109-ZB	GE14-ZB	6,2	✓	0,93 €
AC111-ZB	GE14-ZB	6,8	✓	1,44 €
Stainless steel				
AC101-SS	GE1006-SS	4,7	✓	0,68 €

*Subject to availability - Dimensions in mm

Recommended in case of vibration

GP22
GP23

- **Wide positioning tolerances**
- **Very adaptable**
- **Suitable for vibrations**
- **Materials:**
White zinc steel or stainless steel 303

Assembly


- When used with **AC122** hook, dimension $X = 87\text{mm}$ to withstand a tension of 350N
- Dimension X taken on the first hole of the hook.

Info

- **Not sold individually, please contact us for details**

Accessory

- Hooks **AC122** (tome 1 p.174)

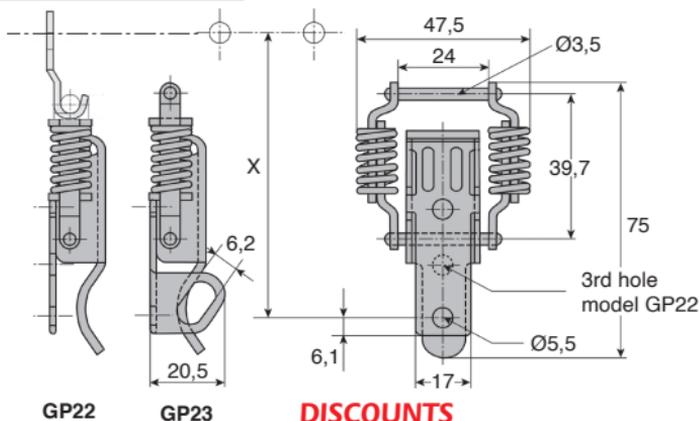

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Material	Wire Ø	Lever thickness	Back-plate thickness	Max. tension (N)	Weight (g)	Stock*	Price each 1 to 50
With padlock holder								
GP22-ZB	Steel	1,7	20/10th	25/10th	450	75	✓	8,59 €
GP22-SS	Stainless steel	2,7	20/10th	25/10th	450	75	✓	17,71 €
Without padlock holder								
GP23-ZB	Steel	2,5	20/10th	25/10th	450	75	✓	8,83 €
GP23-SS	Stainless steel	3,5	20/10th	25/10th	450	75	✓	18,23 €

*Subject to availability - Dimensions in mm

GP75 Recommended in case of vibration


- **High retaining strength for a spring latch**
- Lever can be locked to the mounting bracket by retractable handle
- Easy operation of the release handle
- Can be locked
- Large spring range
- Wide positioning tolerance
- Suitable for vibrations
- Materials:
 - White zinc plated steel
 - 18/8 stainless steel, natural finish

Installation

- Approximate mounting dimension: Using an AC144 catch plate, X = 82.5 mm for a tension of about 550N
- Dimension X taken on the first hole of the hook.

Accessories

- AC144-ZZB and AC144-SS catch plates (tome 1 p.177)

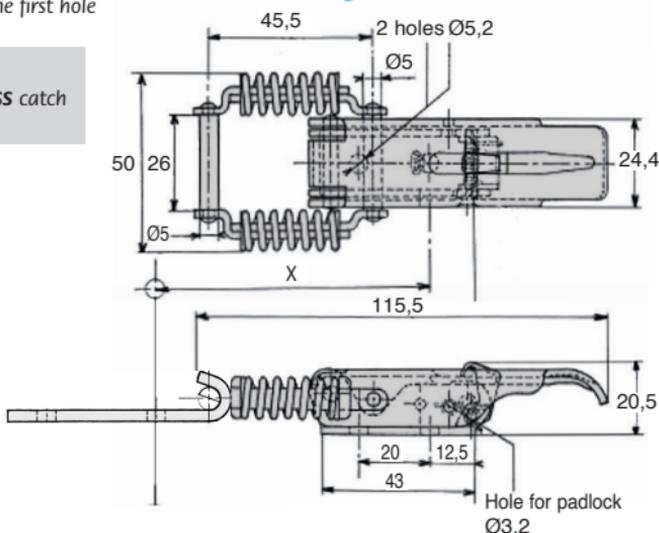

DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part number	Material	Wire Ø	Lever thickness	Mounting plate thickness	Max tension (N)	Weight (g)	Stock*	Price each 1 to 50
GP75-ZB	Steel	5,00	20/10th	20/10th	750	125	✓	12,31 €
GP75-SS	Stainless steel	5,00	20/10th	20/10th	750	125	✓	21,06 €

*Depending on availability - Dimensions in mm


- Closed by latching
- Materials:
White zinc plated steel
18/8 stainless steel, natural finish

Accessories

- GP75-ZB and GP75-SS toggle latches
(tome 1 p.176)



Steel or stainless steel

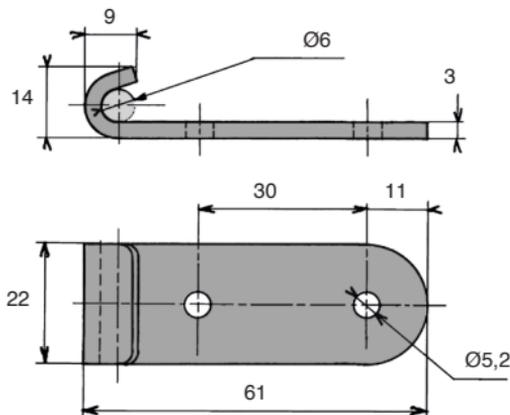

DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part number	Material	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Flat					
AC144-ZB	Steel	GP75-ZB	35	✓	0,98 €
AC144-SS	Stainless steel	GP75-SS	35	✓	3,10 €

*Depending on availability - Dimensions in mm

GE32 For bonnet closures with crushable seals

- Closed by latching
- High strength
- Lever locks on the mounting bracket
- Can be locked
- "Ammunition box" style clasp
- Materials:
 - White zinc plated steel
 - 18/8 stainless steel, natural finish

Steel or stainless steel





Installation

- Approximate mounting dimension: Using an AC157 catch plate, X = 94 mm for a tension of about 150daN (for the long version)
- Dimension X taken on the first hole of the hook.

Accessories

- AC156-ZB, AC156-SS, AC157-ZB and AC157-SS catch plates
(tome 1 p.179)

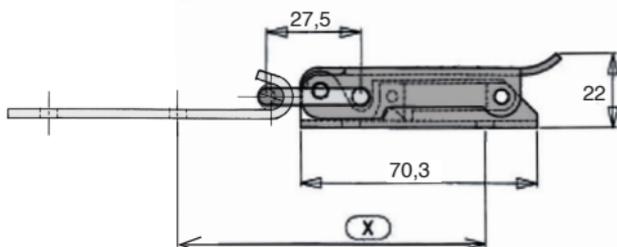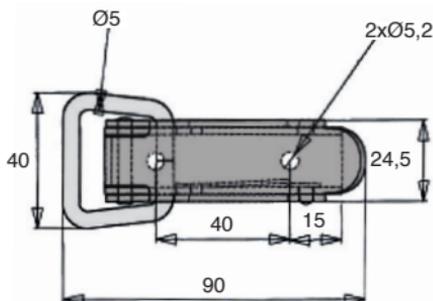

DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part number	Material	Wire Ø	Lever thickness	Mounting plate thickness	Max tension (N)	Weight (g)	Stock*	Price each 1 to 50
GE32-ZB	Steel	5,00	20/10th	20/10th	2500	103	✓	3,17 €
GE32-SS	Stainless steel	5,00	20/10th	20/10th	2500	109	✓	13,02 €

*Depending on availability - Dimensions in mm



- Closed by latching
- Materials:
White zinc plated steel
18/8 stainless steel, natural finish

Accessories

- GE32-ZB and GE32-SS toggle latches
(tome 1 p.178)



Steel or
stainless steel

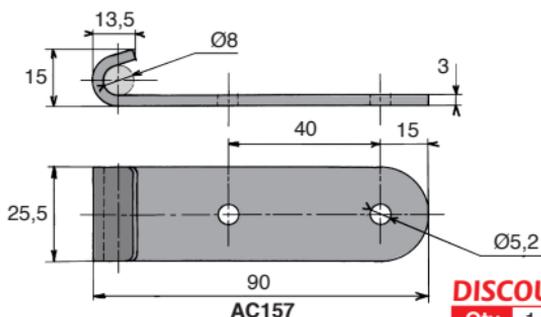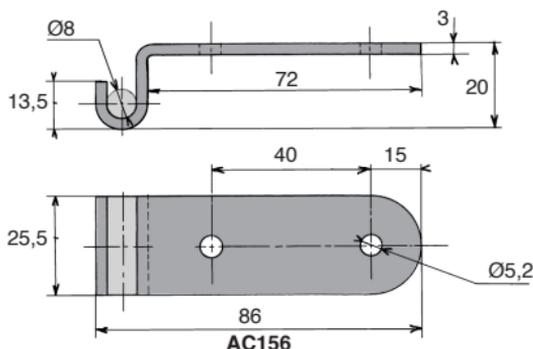

DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part number	Material	Suitable for latch	Weight (g)	Stock*	Price each 1 to 50
Right angled					
AC156-ZB	Steel	GE32-ZB	59	✓	1,24 €
AC156-SS	Stainless steel	GE32-SS	59	✓	4,67 €
Flat					
AC157-ZB	Steel	GE32-ZB	59	✓	1,01 €
AC157-SS	Stainless steel	GE32-SS	59	✓	4,67 €

*Depending on availability - Dimensions in mm