

- Hook fastening
- Material: White zinc steel

Assembly




- GE14-ZB is used with AC101-ZB hook, dimension X = 53.9mm to withstand a tension up to 350N

Advantages

- Flexible positioning
- Can be operated many times without loss of clamping force
- Extended tolerance on positioning

Info.

- Not sold individually, please contact us for details

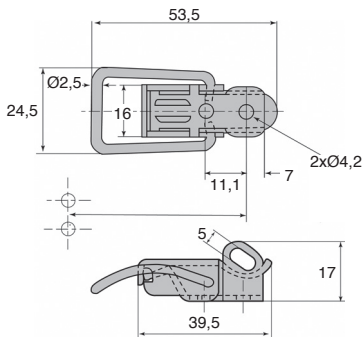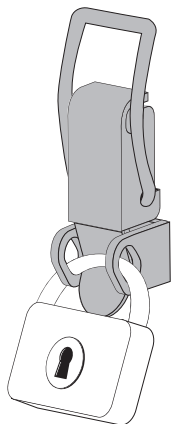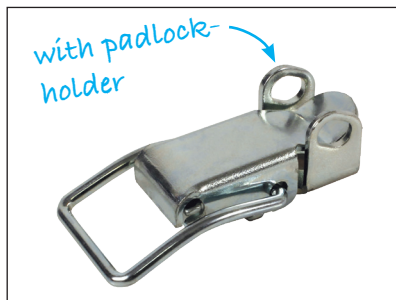

DISCOUNTS

| Qty | 1+ | 51+ | 101+ | 250+ | 400+ | 500+ |
|-------|------|------|------|------|------|------------|
| Disc. | List | -10% | -15% | -20% | -25% | On request |

| Part number | Wire Ø | Lever thickness | Back-plate thickness | Max. tension (N) | Weight (g) | Stock* | Price each 1 to 50 |
|-------------|--------|-----------------|----------------------|------------------|------------|--------|--------------------|
| GE14-ZB | 2,5 | 15/10th | 2mm | 500 | 21,9 | ✓ | 3,39 € |

*Subject to availability - Dimensions in mm

Our other products



EFTC
Fixing support,
Stainless steel



gt64r
Rotating bent lever
with spring, Increased
fitting tolerances



GAL_42
Guide roller for plate
chain return, Without
ball bearing




OPFL_OPPM
Numerical counter
accessories, Locking
clamp



UCFL_PBT
Stainless
steel/Polymer flanged
bearing, Polymer and
stainless steel



ZG0
Plastic spur gear,
Machined plastic
(delrin)

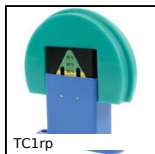


TC1rp
Automatic chain
tensioner, With 180°
guide



FF50
Offset spur gear
reducer, from 111 to
425 Nm



 
CHAEss
Decorative hinge,
Stainless steel



EPRF
High helix leadscrew,
Flanged nut - up to




 CDR
Retaining cable for
ball pin, Retaining



SHTP
Drylin® Linear table,
Economy range

 
Complementary products




AC
Strike for toggle latch,
15mm



 AC
Strike for toggle latch,
15mm



AC
Strike for toggle latch,
15mm

 

AC
Strike for toggle latch,
15mm