

- Hook fastening
- Material: White zinc steel

#### Assembly




- GE14-ZB is used with AC101-ZB hook, dimension X = 53.9mm to withstand a tension up to 350N

#### Advantages

- Flexible positioning
- Can be operated many times without loss of clamping force
- Extended tolerance on positioning

#### Info.

- Not sold individually, please contact us for details

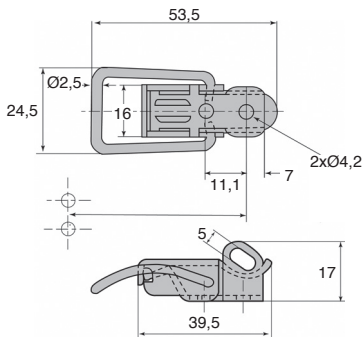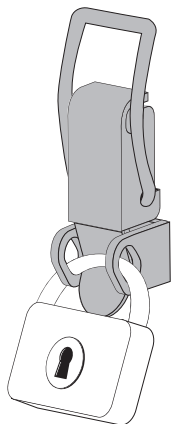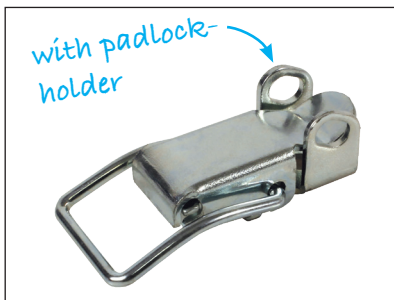

#### DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Wire Ø	Lever thickness	Back-plate thickness	Max. tension (N)	Weight (g)	Stock*	Price each 1 to 50
GE14-ZB	2,5	15/10th	2mm	500	21,9	✓	3,39 €

\*Subject to availability - Dimensions in mm

## Our other products



CNA-CNG

Gas spring, Right angled mounting plate for ball joint



DOMI\_MD

DOMILINE - Rotating table, 40/1



TCL-PD

T-Clip - Aluminium profile attachment, Document holder



 
P70

Worm and wheel gearbox, up to 164 Nm



HTD5M\_25

HTD-type pulley for RPP-type belt, HTD5 Steel




PRF-SCREEN-1

Screen support, Basic support



NKIB

 Index bolt, Spacer for SLB and SLB5 index bolts



PRF PSP\_PR

Cover profile, Inserts into slot



M2

Worm, Machined plastic (delrin)



PF30

Worm and wheel gearbox, up to 8.80 Nm



SLBE

Index bolt, Spacer for SLB and SLB5 index bolts



UGCG

Actuator guide kit, Long housing

## Complementary products



 
AC

Catch plate for toggle latch, 15mm




AC

Catch plate for toggle latch, 15mm



AC

 Catch plate for toggle latch, 15mm



AC

Catch plate for toggle latch, 15mm