

- Hook fastening
- Material: White zinc steel

### Assembly




- GE14-ZB is used with AC101-ZB hook, dimension X = 53.9mm to withstand a tension up to 350N

### Advantages

- Flexible positioning
- Can be operated many times without loss of clamping force
- Extended tolerance on positioning

### Info.

- Not sold individually, please contact us for details

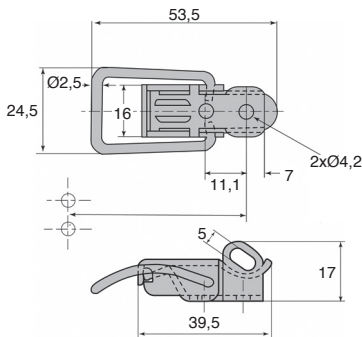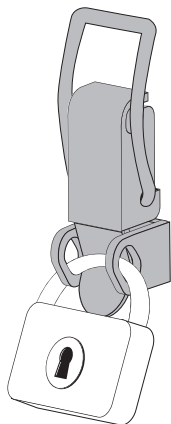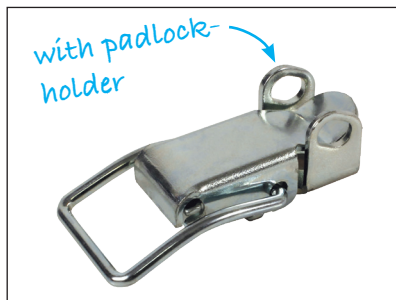

### DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Wire Ø	Lever thickness	Back-plate thickness	Max. tension (N)	Weight (g)	Stock*	Price each 1 to 50
GE14-ZB	2,5	15/10th	2mm	500	21,9	✓	3,39 €

\*Subject to availability - Dimensions in mm

## Our other products



BS3

Panamech, Multi-Beam stainless steel, Stainless steel - with set screw




ACL

Joints for aluminium profile, Variable angle hinge



BAG0

Locking rings in stainless steel, Stainless steel

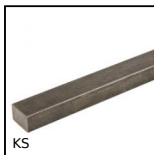

KS

Keysteel, Steel - Keystock



PLC\_PLT

Magnetic stud with threaded hole, With threaded hole



M0

Worm and wheel set, Bronze



VPSS

Small 6 lobe threaded handle - male, Duroplast - Stainless steel



NPTF20

Spacer for tube carrier, Fixing accessory Ø10 to Ø14



PW\_PWG3

Wheel - precision range, Bronze



PTA80

Articulated levelling foot, pressed base



ZG1

Plastic spur gear, Machined plastic



MEB

Moulded plastic bevel gear (nylon), 1:1

## Complementary products



 
AC

Strike for toggle latch, 15mm




AC

Strike for toggle latch, 15mm



AC

Strike for toggle latch, 15mm

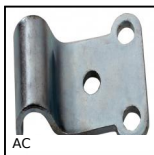

AC

Strike for toggle latch, 15mm