

Rigid toggle latch



GE32

Recommended in case of vibration

- Closed by latching
- High strength
- Lever locks on the mounting bracket (Especially useful in case of vibration).
- Can be locked
- "Ammunition box" style clasp
- Materials:
 - White zinc plated steel
 - 18/8 stainless steel, natural finish


Installation

- Approximate mounting dimension: Using an AC157 catch plate, X = 94 mm for a tension of about 150daN (for the long version)

Accessories

- AC156-ZB, AC156-SS, AC157-ZB and AC157-SS catch plates

Steel or stainless steel

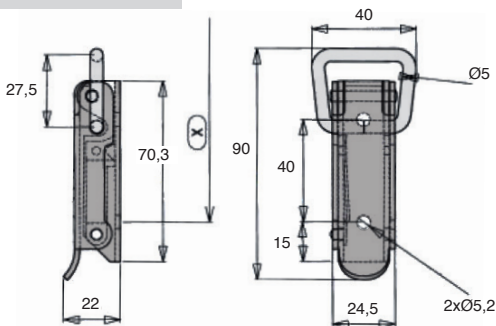

DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Wire Ø	Lever thickness	Mounting plate thickness	Max tension (N)	Weight (g)	Stock*	Price each 1 to 50
GE32-ZB	Steel	5,00	20/10th	20/10th	2500	103	✓	2,80 €
GE32-SS	Stainless steel	5,00	20/10th	20/10th	2500	109	✓	11,50 €

All dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



PVV
Fixed anti-vibration foot mount, Vibration-dampening




EHD16
Internal epicyclic servo reducers, from 210 to 380 Nm



SH2
Parallel axis helical gear, Steel 20NCD2



 GCH
Linear ball slide - Stainless steel balls, Chariot - from 514 N to 1...



CHB
Worm and wheel gear reducer, up to 73 Nm



BFM
Flanged bronze nut, Bronze - 1 thread



H2
Crossed helical gear crossed axis at 90°, Steel 20NCD2



METC
Flanged sintered bronze bush, Self-lubricating sintered bronze



SVG
Adjustable latch clamp with strike plate, Stroke from 118mm to 130,5mm



CHAsb28
Roll of hinge without pin, Plastic hinge



M1
Worm and wheel set, Hardened steel



PPG
Indexing plunger with flange, With horizontal mounting flange

Complementary products



AC156-157
Strike for toggle latch, 25.5mm



AC156-157
Strike for toggle latch, 25.5mm



GE32
Sprung toggle latch with connecting link, Standard



GE14
Toggle latches, With padlock-holder