

# Rigid toggle latch



## GE32

Recommended in case of vibration

- Closed by latching
- High strength
- Lever locks on the mounting bracket (Especially useful in case of vibration).
- Can be locked
- "Ammunition box" style clasp
- Materials:
  - White zinc plated steel
  - 18/8 stainless steel, natural finish


### Installation

- Approximate mounting dimension: Using an AC157 catch plate, X = 94 mm for a tension of about 150daN (for the long version)

### Accessories

- AC156-ZB, AC156-SS, AC157-ZB and AC157-SS catch plates

steel or  
stainless steel

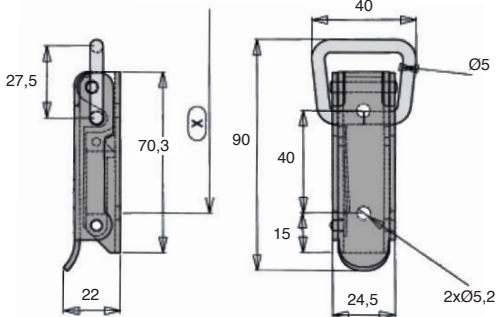

### DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Wire Ø	Lever thickness	Mounting plate thickness	Max tension (N)	Weight (g)	Stock*	Price each 1 to 50
GE32-ZB	Steel	5,00	20/10th	20/10th	2500	103	✓	2,80 €
GE32-SS	Stainless steel	5,00	20/10th	20/10th	2500	109	✓	11,50 €

All dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



RVM14  
Manual worm and  
wheel gearbox,  
Worm/wheel



PSG08  
Spur gear - precision  
range, Case hardened  
steel 20NCD2



AC  
Strike for toggle latch,  
12,13,18 and 20mm



WJUM20  
Drylin® W bearing  
block, Slide



RBGtc  
Swivel castor with  
central hole, Steel -  
grey rubber



DIA  
Ring operated locking  
bolt, with ring




MBF  
Threaded blocking  
clamp, Threaded  
locking clamp



BH01  
Single housed  
bearing, Bearing fitted  
with adhesive



 CHA35  
Hinge for aluminium  
profile, Hinge



PRF-GPA  
Guide for aluminium  
profile, Parallel rails



BPHF  
Ball transfer unit push  
fit, Heavy



DILC  
Indexing plunger with  
cam, with cam

## Complementary products



AC156-157  
Strike for toggle latch,  
25.5mm



AC156-157  
Strike for toggle latch,  
25.5mm



GE32  
Sprung toggle latch  
with connecting link,  
Standard



GE14  
Toggle latches, With  
padlock-holder