

Rigid toggle latch



GE32

Recommended in case of vibration

- Closed by latching
- High strength
- Lever locks on the mounting bracket (Especially useful in case of vibration).
- Can be locked
- "Ammunition box" style clasp
- Materials:
 - White zinc plated steel
 - 18/8 stainless steel, natural finish


Installation

- Approximate mounting dimension: Using an AC157 catch plate, X = 94 mm for a tension of about 150daN (for the long version)

Accessories

- AC156-ZB, AC156-SS, AC157-ZB and AC157-SS catch plates

Steel or stainless steel

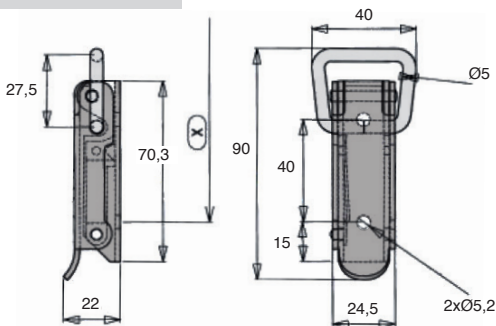

DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Wire Ø	Lever thickness	Mounting plate thickness	Max tension (N)	Weight (g)	Stock*	Price each 1 to 50
GE32-ZB	Steel	5,00	20/10th	20/10th	2500	103	✓	2,80 €
GE32-SS	Stainless steel	5,00	20/10th	20/10th	2500	109	✓	11,50 €

All dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products



IGBSz

Cylindrical ballscrew nut, Cylindrical leadscrew nut



RJUM05

Drylin R® linear bearing housing, Closed - Long



MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



ACLPR

Wheel for aluminium profile, Integrated bearing



MHXred

Reducing sleeve male/female, Hexagonal - stainless steel



TCXR

Automatic chain tensioner, With steel sprocket



PRES

Manual workbench press accessory for PRES-3HR end PRES-4HR, Tool hol...



VPRA_M

Handwheel with handle, Thermosetting plastic - galvanised steel hub



SDB

Locking bolt support bracket, Mounting



SH1

Parallel axis helical gear, Machined plastic



PSPE22

Conical flexible shaft handlee Ø22, Black



DCA

Suction cup, 1.5 bellows, silicon

Complementary products



AC156-157

Strike for toggle latch, 25.5mm



AC156-157

Strike for toggle latch, 25.5mm



GE32

Sprung toggle latch with connecting link, Standard



GE14

Toggle latches, With padlock-holder