

# Rigid toggle latch



## GE32 Recommended in case of vibration

- **Closed by latching**
- High strength
- Lever locks on the mounting bracket (Especially useful in case of vibration).
- Can be locked
- "Ammunition box" style clasp
- Materials:
  - White zinc plated steel
  - 18/8 stainless steel, natural finish

steel or  
stainless steel




### Installation

- Approximate mounting dimension: Using an AC157 catch plate, X = 94 mm for a tension of about 150daN (for the long version)

### Accessories

- AC156-ZB, AC156-SS, AC157-ZB and AC157-SS catch plates

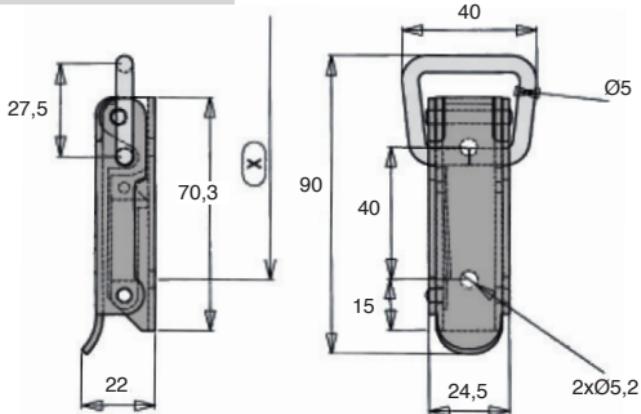


### DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Lever Wire Ø	Mounting plate thickness	Max tension (N)	Weight (g)	Stock*	Price each 1 to 50
GE32-ZB	Steel	5,00	20/10th	20/10th	2500	103	✓ 2,80 €
GE32-SS	Stainless steel	5,00	20/10th	20/10th	2500	109	✓ 11,50 €

All dimensions in mm


## Our other products

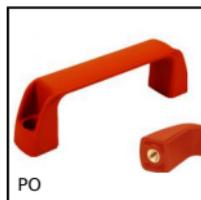

Pull handle - Multi-sector, Tapped recessed insert



Chain sprocket - Stainless steel, 9.525 (DIN 06B-1)

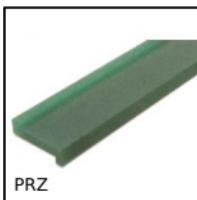

Wear strip for slat top chain, Z profile to be clipped



Mini leadscrew table with metric thread, Base plate




Worm - precision range, Stainless steel



Self-centering clamping hub steel, With lock nut



Ball transfer unit bolt fitting, Heavy

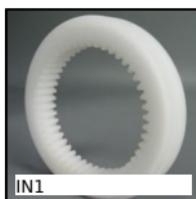

Internal gear, Machined plastic (delrin)



Connection for threaded actuator rod, Connection for



Pull handle, Up to 250 °C



Corner reinforcement, Corner reinforcement



Articulated levelling foot, pressed base Ø80, 10000N

## Complementary products



Strike for toggle latch, 25.5mm



Strike for toggle latch, 25.5mm



Springed toggle latch with connecting link, Standard



Spring loaded toggle latch, Standard (GP75)