

# Rubber latch clamp with strike plate

GEC

Lockable

Suitable for outdoor use

- Snap to close
- Strike plate supplied
- Materials:  
Black elastomer latch clamp  
Stainless steel strike plate

## Advantages

- Internal mechanism: once closed, the hook does not show
- Outdoor use

 


Open






Closed



With strike plate



Small model

 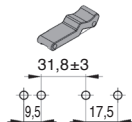 

Large model

  

## DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-3%	-5%	-10%	On request

Part number	Material	Finish	A	B	C	Weight (g)	Stock*	Price each 1 to 9
<b>Small model</b>								
GEC-96	elastomer	black	96,5	29,0	20,0	36	✓	16,97 €
<b>Large model</b>								
GEC-151	elastomer	black	151	45,7	29,5	130	✓	25,08 €

Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

## Our other products



BLH70  
Right angled gearbox,  
from 26 to 128 Nm



UGH32  
H Type Guide units,  
For Ø32 actuators



UFX  
Uneflex® elastic  
coupling, range



PM3  
Worm and wheel set,  
Bronze



 
BAG-MI  
Split shaft collar with  
clamp lever, Steel



PAV  
Fixed anti-vibration  
foot mount, Vibration-  
dampening




TS01\_TW01  
Drylin® T linear slide,  
up to 7000 N



RPP8  
Connecting plate for  
RPP type timing belts,  
RPP8



 HG6-ECO  
Eco range Spur gear,  
Steel C45



ZR  
Plastic rack, Delrin



PRF\_PL\_4590  
Joining plate for  
aluminium profile,



PF40NM  
Worm and wheel gear  
reducer, up to 18 Nm

## Complementary products



GE  
Toggle latches,  
Standard



GP  
Spring loaded toggle  
latch, With padlock-  
holder



SRG  
Adjustable latch  
clamp with strike  
plate, Stroke from  
77,3mm to 83mm



SVG  
Adjustable latch  
clamp with strike  
plate, Stroke from  
82mm to 92mm