

Rubber latch clamp with strike plate

GEC


Lockable

Suitable for outdoor use

- Snap to close
- Strike plate supplied
- Materials:
Black elastomer latch clamp
Stainless steel strike plate

Advantages

- Internal mechanism: once closed, the hook does not show
- Outdoor use

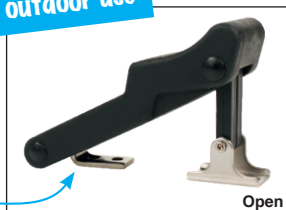


Open






Closed


 
With strike plate



Small model

 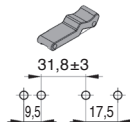 

Large model

  

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-3%	-5%	-10%	On request

Part number	Material	Finish	A	B	C	Weight (g)	Stock*	Price each 1 to 9
Small model								
GEC-96	elastomer	black	96,5	29,0	20,0	36	✓	16,97 €
Large model								
GEC-151	elastomer	black	151	45,7	29,5	130	✓	25,08 €

Dimensions in mm


HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products

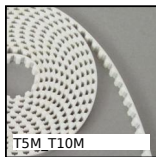

T5M T10M

T type timing belt per metre, T10 Steel cored polyurethane



CAP882

Flexible slat top chain acetal, Large range 882



CHB

Worm and wheel gear reducer, up to 22 Nm



VDSQ

Sliding lock adjustment system, Sliding lock for square profile



SSG1_304L

Stainless steel spur gear, Stainless steel 304L



D19 D29

Compression springs in metre length stainless steel, by the metre



CLM

Male clevis end, Stainless steel short



DIA

Ring operated locking bolt, with ring



SVT15

Screwjack with travelling screw, with translating screw



TOL

Swivel head, Long



CLG2

Moulded plastic spur gear, Moulded plastic (nylon)



M0

Worm and wheel set, Machined plastic (delrin)

Complementary products



GE

Toggle latches, Standard



GP

Spring loaded toggle latch, With padlock-holder



SRG

Adjustable latch clamp with strike plate, Stroke from 77,3mm to 83mm



SVG

Adjustable latch clamp with strike plate, Stroke from 82mm to 92mm