

Rubber latch clamp with strike plate

GEC

Lockable

Suitable for outdoor use

- Snap to close
- Strike plate supplied
- Materials:
Black elastomer latch clamp
Stainless steel strike plate

Advantages

- Internal mechanism: once closed, the hook does not show
- Outdoor use

 


Open






Closed



With strike plate



Small model

 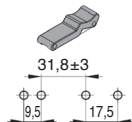 

Large model

  

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-3%	-5%	-10%	On request

Part number	Material	Finish	A	B	C	Weight (g)	Stock*	Price each 1 to 9
Small model								
GEC-96	elastomer	black	96,5	29,0	20,0	36	✓	16,97 €
Large model								
GEC-151	elastomer	black	151	45,7	29,5	130	✓	25,08 €

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products



BL8

Right angled gearbox,
from 0.20 to 2 Nm



T25-6ECO

T type timing pulley,
Economy range - T2.5
aluminium



HK

Manual locking clamp,
Manual locking clamp
LWL



PTAF80-PAMF80

Articulated fixable
foot with pressed
base Ø80, Ø 80




CHTRP

Single and dual
output gearboxes, Up
to 9,1 Nm



CLG2

 Moulded plastic spur
gear, Moulded plastic
(nylon)



RDE-W

Sealing washer
Hygienic Usit®,
Stainless steel - White
EPDM



E50

Right angle helical
reducers, from 3 to 41
Nm



AC156-157

Strike for toggle latch,
25.5mm



DOG111

Motor-gearbox 12V
and 24V DC, from 1.5



PRF_BV

Screw block, Panel
addition and fastening



DOMI50

Accessories, Plate

Complementary products



GE

Toggle latches,
Standard



GP

Spring loaded toggle
latch, With padlock-
holder



SRG

Adjustable latch
clamp with strike
plate, Stroke from
77,3mm to 83mm



SVG

Adjustable latch
clamp with strike
plate, Stroke from
82mm to 92mm