

GEES


Steel/steel contact

- DIN 648, series E, ISO 6124/1
- Material: steel

Info.

- Some maintenance required (except GE-E models)

Economy range

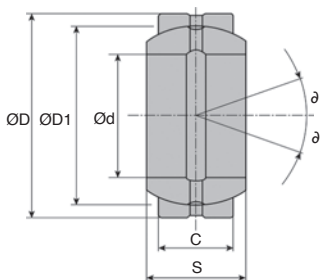

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List	-10%	-15%	-20%	-30%	On request

Part number	Od	OD	OD1	S	C	δ	static (N)	dynamic (N)	Weight (g)	Stock*	Price each 1 to 5
GE6E	6 ^{-0.008}	14 ^{-0.008}	10,0	6 ^{-0.12}	4 ^{+0.24}	13°	17000	3400	<10	✓	2,92 €
GE8E	8 ^{-0.008}	16 ^{-0.008}	13,0	8 ^{-0.12}	5 ^{+0.24}	15°	27500	5500	<10	✓	2,92 €
GE10E	10 ^{-0.008}	19 ^{-0.008}	16,0	9 ^{-0.12}	6 ^{+0.24}	12°	40500	8150	10	✓	2,92 €
GE12E	12 ^{-0.008}	22 ^{-0.008}	18,0	10 ^{-0.12}	7 ^{+0.24}	11°	54000	10800	10	✓	2,92 €
GE15ES	15 ^{-0.008}	26 ^{-0.008}	22,0	12 ^{-0.12}	9 ^{+0.24}	8°	85000	17000	20	✓	2,92 €
GE17ES	17 ^{-0.008}	30 ^{-0.008}	25,0	14 ^{-0.12}	10 ^{+0.24}	10°	106000	21200	40	✓	3,16 €
GE20ES	20 ^{-0.010}	35 ^{+0.011}	29,0	16 ^{-0.12}	12 ^{+0.24}	9°	146000	30000	60	✓	3,16 €
GE25ES	25 ^{-0.010}	42 ^{+0.011}	35,5	20 ^{-0.12}	16 ^{+0.24}	7°	240000	48000	110	✓	3,66 €
GE30ES	30 ^{-0.010}	47 ^{+0.011}	40,7	22 ^{-0.12}	18 ^{+0.24}	6°	310000	62000	140	✓	4,63 €
GE35ES	35 ^{-0.012}	55 ^{+0.013}	47,0	25 ^{-0.12}	20 ^{+0.30}	6°	400000	80000	220	-	6,35 €
GE40ES	40 ^{-0.012}	62 ^{+0.015}	53,0	28 ^{-0.12}	22 ^{+0.30}	7°	500000	100000	300	✓	8,33 €
GE45ES	45 ^{-0.012}	68 ^{+0.013}	60,0	32 ^{-0.12}	25 ^{+0.30}	7°	640000	127000	400	-	9,29 €
GE50ES	50 ^{-0.012}	75 ^{+0.013}	66,0	35 ^{-0.12}	28 ^{+0.30}	6°	780000	156000	540	✓	11,76 €
GE60ES	60 ^{-0.015}	90 ^{+0.015}	80,0	44 ^{-0.15}	36 ^{+0.40}	6°	1220000	245000	1000	✓	20,62 €
GE70ES	70 ^{-0.015}	105 ^{+0.015}	92,0	49 ^{-0.15}	40 ^{+0.40}	6°	1560000	315000	1500	-	26,03 €
GE80ES	80 ^{-0.015}	120 ^{+0.015}	105,0	55 ^{-0.15}	45 ^{+0.40}	6°	2000000	400000	2200	-	38,83 €
GE90ES	90 ^{-0.020}	130 ^{+0.018}	115,0	60 ^{-0.20}	50 ^{+0.50}	5°	2450000	490000	2700	-	63,44 €
GE100ES	100 ^{-0.020}	150 ^{+0.018}	130,0	70 ^{-0.20}	55 ^{+0.50}	7°	3050000	610000	4300	-	88,04 €
GE110ES	110 ^{-0.020}	160 ^{+0.025}	140,0	70 ^{-0.20}	55 ^{+0.50}	6°	3250000	655000	4700	-	132,32 €

*Depending on availability - Dimensions in mm

Our other products



SRG

Adjustable latch clamp with strike plate, Stroke from 117,4mm to 128mm



BLH50

Right angled gearbox, from 7.70 to 20 Nm



SLVHlok

Vertical toggle clamp, Vertical toggle clamp / horizontal foot



PCS37

Chain sprocket - steel, 9.525mm (DIN06B-1)




PSG1HC

Skive hobbed spur gears - precision range, Case hardened steel 20NCD2



WTM

Tightening washer - DIN6340, Steel

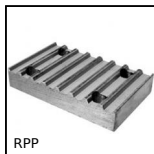


RPP

Connecting plate for RPP type timing belts, RRP5



LVT

 Miniature motorised actuator 4A, 4 amperes



BTESS

Universal stainless steel arm for



ACLBTS

Closing system for aluminium profile,



ACL-APB

Closing system for aluminium profile,



BIM

Indexing plunger mini, miniature

Complementary products



GE_ES_2RS

Spherical bushing, Steel / steel with seals



GE_C

Spherical bushing, Hard chromium / PTFE