


- DIN 648, series E, ISO 6124/1
- Material: steel

Info.

- Requires maintenance

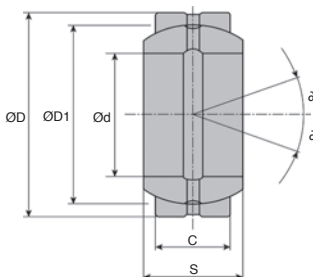


DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List	-10%	-15%	-20%	-30%	On request

Part number	Ød	ØD	ØD1	S	C	α	Load capacity		Weight (g)	Stock*	Price each 1 to 5
							static (N)	dynamic (N)			
GE15ES-2RS	15 ^{+0.008}	26 ^{+0.009}	22,0	12 ^{+0.12}	9 ^{+0.24}	8°	85000	17000	20	-	3,66 €
GE17ES-2RS	17 ^{+0.008}	30 ^{+0.009}	25,0	14 ^{+0.12}	10 ^{+0.24}	10°	106000	21200	40	✓	3,91 €
GE20ES-2RS	20 ^{+0.010}	35 ^{+0.011}	29,0	16 ^{+0.12}	12 ^{+0.24}	9°	146000	30000	60	✓	4,14 €
GE25ES-2RS	25 ^{+0.010}	42 ^{+0.011}	35,5	20 ^{+0.12}	16 ^{+0.24}	7°	240000	48000	110	✓	5,13 €
GE30ES-2RS	30 ^{+0.010}	47 ^{+0.011}	40,7	22 ^{+0.12}	18 ^{+0.24}	6°	310000	62000	140	✓	5,87 €
GE35ES-2RS	35 ^{+0.012}	55 ^{+0.013}	47,0	25 ^{+0.12}	20 ^{+0.30}	6°	400000	80000	220	✓	7,35 €
GE40ES-2RS	40 ^{+0.012}	62 ^{+0.013}	53,0	28 ^{+0.12}	22 ^{+0.30}	7°	500000	100000	300	✓	9,08 €
GE45ES-2RS	45 ^{+0.012}	68 ^{+0.013}	60,0	32 ^{+0.12}	25 ^{+0.30}	7°	640000	127000	400	-	10,79 €
GE50ES-2RS	50 ^{+0.012}	75 ^{+0.013}	66,0	35 ^{+0.12}	28 ^{+0.30}	6°	780000	156000	540	-	14,21 €
GE60ES-2RS	60 ^{+0.015}	90 ^{+0.015}	80,0	44 ^{+0.15}	36 ^{+0.40}	6°	1220000	245000	1000	-	22,12 €
GE70ES-2RS	70 ^{+0.015}	105 ^{+0.015}	92,0	49 ^{+0.15}	40 ^{+0.40}	6°	1560000	315000	1500	-	28,99 €
GE80ES-2RS	80 ^{+0.015}	120 ^{+0.015}	105,0	55 ^{+0.15}	45 ^{+0.40}	6°	2000000	400000	2200	-	45,73 €
GE90ES-2RS	90 ^{+0.020}	130 ^{+0.018}	115,0	60 ^{+0.20}	50 ^{+0.50}	5°	2450000	490000	2700	-	71,30 €
GE100ES-2RS	100 ^{+0.020}	150 ^{+0.018}	130,0	70 ^{+0.20}	55 ^{+0.50}	7°	3050000	610000	4300	-	95,92 €
GE110ES-2RS	110 ^{+0.020}	160 ^{+0.025}	140,0	70 ^{+0.20}	55 ^{+0.50}	6°	3250000	655000	4700	-	147,07 €

*Depending on availability - Dimensions in mm

 Our other products



CDRs

Retaining cable for ball pin, Retaining cable



CHA138

Screwed hinge with threaded insert, 138 degrees



BFM2

Flanged bronze nut, Bronze - 2 threads



BIM

Indexing plunger mini, miniature



CHAR

Spring hinge for screw mounting, screwed



WINGbr

Wing screw, hand tightened DIN316, Brass DIN 316



LWL

Linear ball slide - Stainless steel balls, Chariot - from 514 N to 1...



PSG1

Spur gear - precision range, Pre-hardened Steel 35NCD6



BABam

Self-locking ball pin lifting ring for



DIV_SS

Stainless steel locking bolt, With grip -



ATZY

Diabolo shaped elasto mount, Steel



P40

Worm and wheel gear reducer, up to 18 Nm

Complementary products



GE_ES

Spherical bushing, Steel / steel



GE_ET_2RS

Spherical bushing, Hard chromium / Teflon contact with seals