


## Module 2.0

Heat treated steel



- Ground spur gear, precision JIS B1702 grade 3
- Pressure angle 20°
- Material: steel S45C
- Tooth surfaces induction hardened
- Surface hardness 48-53HRC
- Datum reference surface for teeth grinding: bore

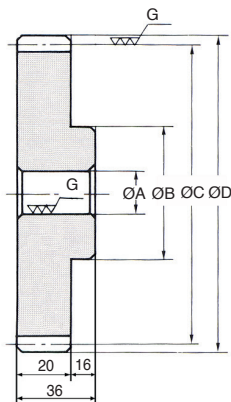

### DISCOUNTS

Qty	1+	2+	3+
Disc.	List	-20%	On request

Part number	Z Teeth	ØP PCD	ØD Outside	ØM Boss	ØA Bore	Backlash (mm)	Weight (kg)	Price each
GG2-14	14	28	32	22	12	0,10-0,20	0,10	125,40 €
GG2-15	15	30	34	24	12	0,10-0,20	0,18	130,20 €
GG2-16	16	32	36	26	12	0,10-0,20	0,18	134,61 €
GG2-17	17	34	38	28	12	0,10-0,20	0,19	140,57 €
GG2-18	18	36	40	30	12	0,10-0,20	0,25	145,37 €
GG2-19	19	38	42	31	12	0,10-0,20	0,24	148,97 €
GG2-20	20	40	44	32	15	0,10-0,20	0,31	149,77 €
GG2-21	21	42	46	34	15	0,10-0,20	0,28	150,54 €
GG2-22	22	44	48	36	15	0,10-0,20	0,38	154,53 €
GG2-23	23	46	50	37	15	0,10-0,20	0,35	161,71 €

Dimensions in mm

## DISCOUNTS

Qty	1+	2+	3+
Disc.	List	-20%	On request

Part number	Z Teeth	ØP PCD	ØD Outside	ØM Boss	ØA Bore	Backlash (mm)	Weight (kg)	Price each
GG2-24	24	48	52	38	15	0,10-0,20	0,45	165,28 €
GG2-25	25	50	54	40	15	0,10-0,20	0,49	166,50 €
GG2-26	26	52	56	42	15	0,12-0,22	0,46	176,87 €
GG2-27	27	54	58	44	15	0,12-0,22	0,50	178,44 €
GG2-28	28	56	60	45	15	0,12-0,22	0,61	184,39 €
GG2-29	29	58	62	48	15	0,12-0,22	0,59	186,04 €
GG2-30	30	60	64	50	18	0,12-0,22	0,67	190,44 €
GG2-32	32	64	68	50	18	0,12-0,22	0,74	197,62 €
GG2-34	34	68	72	50	18	0,12-0,22	0,75	211,11 €
GG2-35	35	70	74	50	18	0,12-0,22	0,84	219,45 €
GG2-36	36	72	76	50	18	0,12-0,22	0,88	221,91 €
GG2-38	38	76	80	50	18	0,12-0,22	0,89	237,06 €
GG2-40	40	80	84	60	20	0,12-0,22	1,10	260,15 €
GG2-42	42	84	88	60	20	0,12-0,22	1,10	268,13 €
GG2-44	44	88	92	60	20	0,12-0,22	1,20	283,67 €
GG2-45	45	90	94	60	20	0,12-0,22	1,30	292,01 €
GG2-48	48	96	100	60	20	0,12-0,22	1,50	318,37 €
GG2-50	50	100	104	60	25	0,12-0,22	1,60	329,11 €
GG2-55	55	110	114	60	25	0,14-0,24	1,70	362,93 €
GG2-56	56	112	116	60	25	0,14-0,24	1,80	369,36 €
GG2-60	60	120	124	65	25	0,14-0,24	2,20	403,56 €
GG2-64	64	128	132	65	25	0,14-0,24	2,30	442,29 €
GG2-70	70	140	144	70	25	0,14-0,24	2,90	487,29 €
GG2-75	75	150	154	70	25	0,14-0,24	3,10	542,28 €
GG2-80	80	160	164	80	25	0,14-0,24	3,80	575,38 €
GG2-90	90	180	184	80	25	0,14-0,24	4,50	681,42 €
GG2-100	100	200	204	80	25	0,14-0,24	5,40	799,38 €

Dimensions in mm

## Our other products



UCFL  
Cast iron flanged bearing, Cast iron



ACL-PL  
Joining plate for aluminium profile, Joint plate - 86x86 mm



DIV\_SS  
Stainless steel locking bolt, With grip - Stainless steel



STL  
Guidance brush - Rail, Rail



JCDss  
Double universal joint - Stainless steel, Low duty



MSP23  
Masterplate® glueable insert Ø23, Cylindrical Ø23 with threaded s...



NCT  
Square tube connector, Fixed angle



LC  
Friction clutch, 190 to 1800 Nm



YG0  
HEAVY DUTY spur gear, Steel 35NCD6



SEV  
Vertical stirrup toggle clamp, Vertical Latch Clamp - steel



HRV  
V- rail guidance Simple Select® system, Rail with



PTA50ssEB  
Articulated foot with sheet metal base Ø50, Articulated foot

Complementary products