


Module 2.0

Heat treated steel



- Ground spur gear, precision JIS B1702 grade 3
- Pressure angle 20°
- Material: steel S45C
- Tooth surfaces induction hardened
- Surface hardness 48-53HRC
- Datum reference surface for teeth grinding: bore

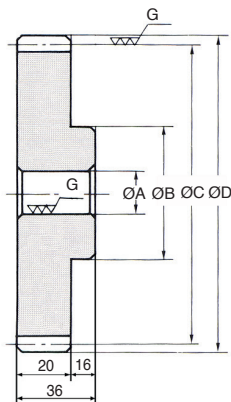

DISCOUNTS

| | | | |
|-------|------|------|------------|
| Qty | 1+ | 2+ | 3+ |
| Disc. | List | -20% | On request |

| Part number | Z Teeth | ØP PCD | ØD Outside | ØM Boss | ØA Bore | Backlash (mm) | Weight (kg) | Price each |
|-------------|------------|-----------|---------------|------------|------------|------------------|----------------|------------|
| GG2-14 | 14 | 28 | 32 | 22 | 12 | 0,10-0,20 | 0,10 | 125,40 € |
| GG2-15 | 15 | 30 | 34 | 24 | 12 | 0,10-0,20 | 0,18 | 130,20 € |
| GG2-16 | 16 | 32 | 36 | 26 | 12 | 0,10-0,20 | 0,18 | 134,61 € |
| GG2-17 | 17 | 34 | 38 | 28 | 12 | 0,10-0,20 | 0,19 | 140,57 € |
| GG2-18 | 18 | 36 | 40 | 30 | 12 | 0,10-0,20 | 0,25 | 145,37 € |
| GG2-19 | 19 | 38 | 42 | 31 | 12 | 0,10-0,20 | 0,24 | 148,97 € |
| GG2-20 | 20 | 40 | 44 | 32 | 15 | 0,10-0,20 | 0,31 | 149,77 € |
| GG2-21 | 21 | 42 | 46 | 34 | 15 | 0,10-0,20 | 0,28 | 150,54 € |
| GG2-22 | 22 | 44 | 48 | 36 | 15 | 0,10-0,20 | 0,38 | 154,53 € |
| GG2-23 | 23 | 46 | 50 | 37 | 15 | 0,10-0,20 | 0,35 | 161,71 € |

Dimensions in mm

DISCOUNTS

| | | | |
|-------|------|------|------------|
| Qty | 1+ | 2+ | 3+ |
| Disc. | List | -20% | On request |

| Part number | Z Teeth | ØP PCD | ØD Outside | ØM Boss | ØA Bore | Backlash (mm) | Weight (kg) | Price each |
|-------------|------------|-----------|---------------|------------|------------|------------------|----------------|------------|
| GG2-24 | 24 | 48 | 52 | 38 | 15 | 0,10-0,20 | 0,45 | 165,28 € |
| GG2-25 | 25 | 50 | 54 | 40 | 15 | 0,10-0,20 | 0,49 | 166,50 € |
| GG2-26 | 26 | 52 | 56 | 42 | 15 | 0,12-0,22 | 0,46 | 176,87 € |
| GG2-27 | 27 | 54 | 58 | 44 | 15 | 0,12-0,22 | 0,50 | 178,44 € |
| GG2-28 | 28 | 56 | 60 | 45 | 15 | 0,12-0,22 | 0,61 | 184,39 € |
| GG2-29 | 29 | 58 | 62 | 48 | 15 | 0,12-0,22 | 0,59 | 186,04 € |
| GG2-30 | 30 | 60 | 64 | 50 | 18 | 0,12-0,22 | 0,67 | 190,44 € |
| GG2-32 | 32 | 64 | 68 | 50 | 18 | 0,12-0,22 | 0,74 | 197,62 € |
| GG2-34 | 34 | 68 | 72 | 50 | 18 | 0,12-0,22 | 0,75 | 211,11 € |
| GG2-35 | 35 | 70 | 74 | 50 | 18 | 0,12-0,22 | 0,84 | 219,45 € |
| GG2-36 | 36 | 72 | 76 | 50 | 18 | 0,12-0,22 | 0,88 | 221,91 € |
| GG2-38 | 38 | 76 | 80 | 50 | 18 | 0,12-0,22 | 0,89 | 237,06 € |
| GG2-40 | 40 | 80 | 84 | 60 | 20 | 0,12-0,22 | 1,10 | 260,15 € |
| GG2-42 | 42 | 84 | 88 | 60 | 20 | 0,12-0,22 | 1,10 | 268,13 € |
| GG2-44 | 44 | 88 | 92 | 60 | 20 | 0,12-0,22 | 1,20 | 283,67 € |
| GG2-45 | 45 | 90 | 94 | 60 | 20 | 0,12-0,22 | 1,30 | 292,01 € |
| GG2-48 | 48 | 96 | 100 | 60 | 20 | 0,12-0,22 | 1,50 | 318,37 € |
| GG2-50 | 50 | 100 | 104 | 60 | 25 | 0,12-0,22 | 1,60 | 329,11 € |
| GG2-55 | 55 | 110 | 114 | 60 | 25 | 0,14-0,24 | 1,70 | 362,93 € |
| GG2-56 | 56 | 112 | 116 | 60 | 25 | 0,14-0,24 | 1,80 | 369,36 € |
| GG2-60 | 60 | 120 | 124 | 65 | 25 | 0,14-0,24 | 2,20 | 403,56 € |
| GG2-64 | 64 | 128 | 132 | 65 | 25 | 0,14-0,24 | 2,30 | 442,29 € |
| GG2-70 | 70 | 140 | 144 | 70 | 25 | 0,14-0,24 | 2,90 | 487,29 € |
| GG2-75 | 75 | 150 | 154 | 70 | 25 | 0,14-0,24 | 3,10 | 542,28 € |
| GG2-80 | 80 | 160 | 164 | 80 | 25 | 0,14-0,24 | 3,80 | 575,38 € |
| GG2-90 | 90 | 180 | 184 | 80 | 25 | 0,14-0,24 | 4,50 | 681,42 € |
| GG2-100 | 100 | 200 | 204 | 80 | 25 | 0,14-0,24 | 5,40 | 799,38 € |

Dimensions in mm

Our other products



BETASS

Hitch pin, Hitch



PTKFss

Fixable foot for the food industry, Stainless steel - 3-A standard



PR821

Idler sprocket for slat top chain, Ranges 821 and 805



SH0

Parallel axis helical gear, Steel 20NCD2



PTGP

Tensioner pulley, For flat belts



DOMI50

Connecting kits, XZ linking kit



NSU

Universal 90° support clamp, Universal 90° support clamp



TCXR

Automatic chain tensioner, With stainless steel sprocket



PR105

Articulated foot Ø103, Ø 103



NCT

Square tube connector, Fixed angle



OP7

Mechanical digital position indicator, 5 numbers



RT25

Self-centering flanged locking assembly, Medium/high torque

Complementary products