

# Female wing knob

Stock


GGB

Technopolymer with brass insert

- Female wing knob with tapped hole (blind or fully threaded)
- For manual tightening
- Material:  
Matt black polyamide with brass insert

## Info.

- Not sold individually, please contact us for details

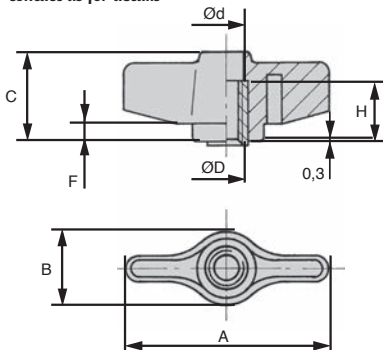

with brass insert

## DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	B	C	ØD	Ød	H	F	Stock*	Price each 1 to 9
<b>Knob with blind thread</b>									
GGB34-M6	34	14	18	M6	-	9	4	✓	1,88 €
GGB34-M8	34	14	18	M8	-	9	4	✓	1,88 €
GGB40-M6	40	15	19	M6	-	9	4	✓	1,98 €
GGB40-M8	40	15	19	M8	-	9	4	✓	1,98 €
GGB48-M6	48	17	20	M6	-	13	4	-	2,06 €
GGB48-M8	48	17	20	M8	-	13	4	✓	2,06 €
<b>Knob, fully threaded</b>									
GGB34-M6/FP	34	14	18	M6	7	15	4	✓	2,06 €
GGB40-M6/FP	40	15	19	M6	9	15	4	✓	2,11 €
GGB40-M8/FP	40	15	19	M8	9	15	4	✓	2,11 €
GGB48-M6/FP	48	17	20	M6	9	15	4	✓	2,21 €
GGB48-M8/FP	48	17	20	M8	9	15	4	✓	2,21 €

\*Depending on availability - Dimensions in mm

## Our other products



YG1

HEAVY DUTY spur gear, Steel 35NCD6



KB\_UU

Closed linear precision bearing, Precision - steel



GE

Toggle latches, Standard



RURp

Swivel castor with double brake, Polyurethane - Aluminium rim (Free



RVM25

Manually operated gearbox, Bevel



PSG25

Spur gear - precision range, Stainless steel 303



E60

Right angle helical reducers, from 4.50 to 62 Nm



PRF\_PSA

Shaft support for aluminium profile, Linear guide shaft



SRG

Adjustable latch clamp with strike



 
AFM

Flanged polymer bush, Food grade



MFB

Flexible bellows coupling, Aluminium



STL

Guidance brush - Brush, Brush

## Complementary products



GGB

Female wing knob, With blind thread



GGP

Male wing knob, Technopolymer with brass spindle



PVL

Small lobed handle, Polyamide