

Female wing knob

Stock


GGB

Technopolymer with brass insert

- Female wing knob with tapped hole (blind or fully threaded)
- For manual tightening
- Material:
Matt black polyamide with brass insert

Info.

- Not sold individually, please contact us for details

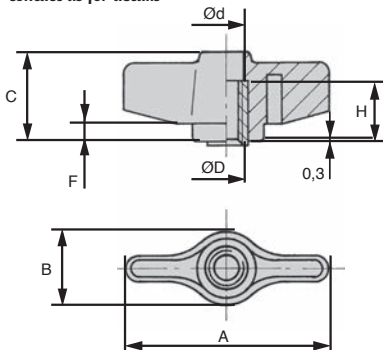

with brass insert

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	B	C	ØD	Ød	H	F	Stock*	Price each 1 to 9
Knob with blind thread									
GGB34-M6	34	14	18	M6	-	9	4	✓	1,88 €
GGB34-M8	34	14	18	M8	-	9	4	✓	1,88 €
GGB40-M6	40	15	19	M6	-	9	4	✓	1,98 €
GGB40-M8	40	15	19	M8	-	9	4	✓	1,98 €
GGB48-M6	48	17	20	M6	-	13	4	-	2,06 €
GGB48-M8	48	17	20	M8	-	13	4	✓	2,06 €
Knob, fully threaded									
GGB34-M6/FP	34	14	18	M6	7	15	4	✓	2,06 €
GGB40-M6/FP	40	15	19	M6	9	15	4	✓	2,11 €
GGB40-M8/FP	40	15	19	M8	9	15	4	✓	2,11 €
GGB48-M6/FP	48	17	20	M6	9	15	4	✓	2,21 €
GGB48-M8/FP	48	17	20	M8	9	15	4	✓	2,21 €

*Depending on availability - Dimensions in mm

Our other products



 
PDM_PDV
Detectable plastic palm grip, blue thermoplastic



EKONSL
Silicone conical elasto buffer, Female mounting



SSG2_304L
Stainless steel spur gear, Stainless steel 304L



GLT3-76
Telescopic drawer,



P60
Worm and wheel gear reducer, up to 118 Nm



PCF2
Conical flexible mount, Oval base plate



NRV
Orthogonal support clamp, Orthogonal support clamp



DER63
Stainless steel AC asynchronous motor 0.18 kW, 0.18kW



PDD
Actuating plunger, Non-rotating detector



VRBS
Folding lifting ring for welding, Folding - for



BMM
Knurled knob - male, Knurled



BSPT
Single rod clip, Round

Complementary products



GGB
Female wing knob, Fully threaded



GGP
Male wing knob, Technopolymer with stainless steel spindle