

# Female wing knob


Stock

**GGB** Technopolymer with brass insert

- Female wing knob with tapped hole (blind or fully threaded)
- For manual tightening
- Material:  
Matt black polyamide with brass insert

## Info.

- Not sold individually, please contact us for details

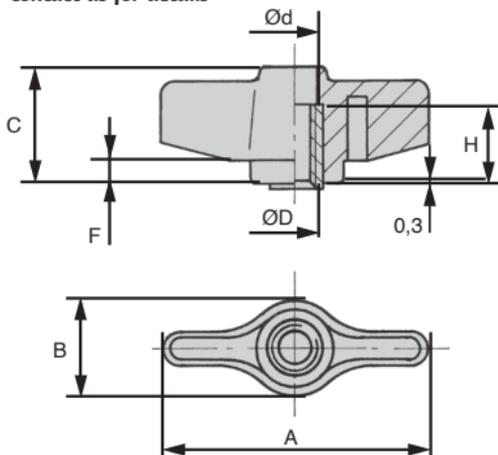

Brass insert

## DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	B	C	ØD	Ød	H	F	Stock*	Price each 1 to 9
<b>Knob with blind thread</b>									
GGB34-M6	34	14	18	M6	-	9	4	✓	2,22 €
GGB34-M8	34	14	18	M8	-	9	4	-	2,22 €
GGB40-M6	40	15	19	M6	-	9	4	✓	2,34 €
GGB40-M8	40	15	19	M8	-	9	4	-	2,34 €
GGB48-M6	48	17	20	M6	-	13	4	-	2,46 €
GGB48-M8	48	17	20	M8	-	13	4	✓	2,46 €
<b>Knob, fully threaded</b>									
GGB34-M6/FP	34	14	18	M6	7	15	4	✓	2,46 €
GGB40-M6/FP	40	15	19	M6	9	15	4	✓	2,53 €
GGB40-M8/FP	40	15	19	M8	9	15	4	✓	2,53 €
GGB48-M6/FP	48	17	20	M6	9	15	4	✓	2,65 €
GGB48-M8/FP	48	17	20	M8	9	15	4	✓	2,65 €

\*Subject to availability - Dimensions in mm

**Technopolymer,**

**GGP**



with steel or stainless steel spindle

- Male wing knob
- For manual tightening
- Material:  
Matt black polyamide
- Threaded shaft: zinc plated steel or stainless steel

**Info.**

- Not sold individually, please contact us for details

Spindle plated  
steel or  
stainless steel

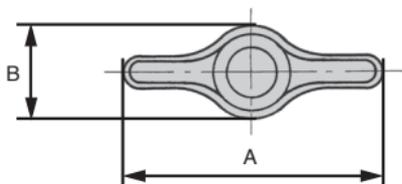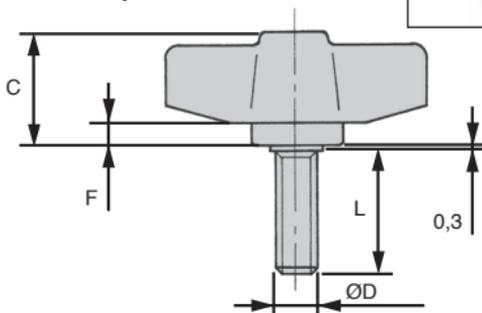

**DISCOUNTS**

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	B	C	ØD	L	F	Stock*	Price each 1 to 9
<b>Steel</b>								
GGP34-M6-25	34	14	18	M6	25	4	✓	2,46 €
GGP34-M8-25	34	14	18	M8	25	4	✓	2,65 €
GGP40-M8-25	40	15	19	M8	25	4	-	2,88 €
GGP48-M8-25	48	17	20	M8	25	4	✓	3,38 €
GGP48-M8-40	48	17	20	M8	40	4	✓	3,44 €
<b>Stainless steel</b>								
GGP34-M6-20/SS	34	14	18	M6	20	4	✓	5,34 €
GGP34-M6-30/SS	34	14	18	M6	30	4	-	5,62 €

\*Subject to availability - Dimensions in mm